


E18207



Female cordset

ADOGA030VAS0010E03

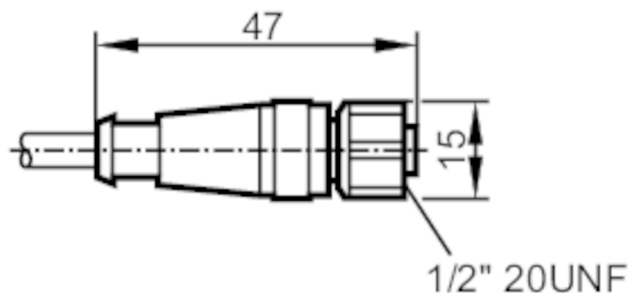

Application

System	gold-plated contacts
--------	----------------------

Electrical data

Operating voltage	[V]	< 300 AC/DC
-------------------	-----	-------------

Operating conditions

Ambient temperature	[°C]	-10...100
Protection		IP 68

Mechanical data

Weight	[g]	361.966
Dimensions	[mm]	15 x 15 x 47
Material		PVC
Molded-body material		PVC
Material nut		stainless steel (1.4571/316Ti)

Remarks

Pack quantity	1 pcs.
---------------	--------

E18207



Female cordset

ADOGA030VAS0010E03

Electrical connection


Cable: 10 m, PVC, yellow; 3 x 0.34 mm² / AWG 22

Electrical connection - Socket

Connector: 1 x 1/2", straight; coding: C; Moulded body: PVC; Locking: stainless steel (1.4571/316Ti); Contacts: gold-plated



Connection

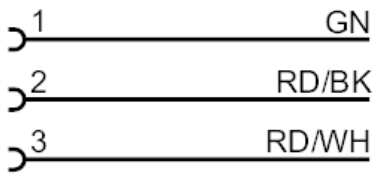

GN =
RD/BK =
RD/WH =

Core colors :
green
red/black
red/white