


E18208



Female cordset

ADOGA030VAS0025E03

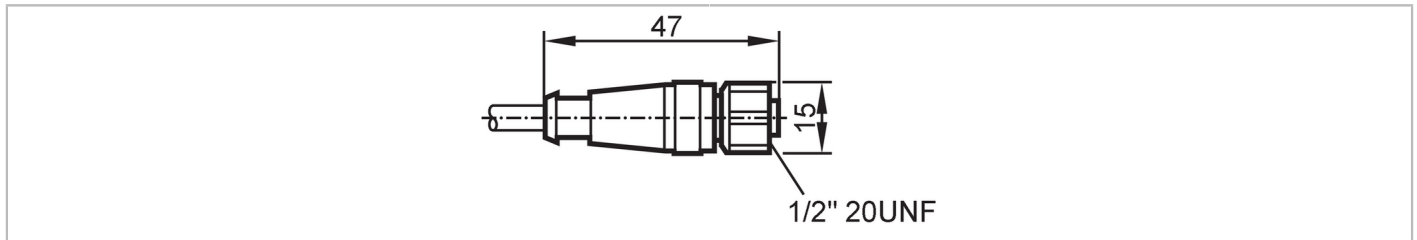

Application

Special feature	gold-plated contacts
Application	sanitary and wet areas in the food industry

Electrical data

Operating voltage	[V]	< 300 AC/DC
-------------------	-----	-------------

Operating conditions

Ambient temperature	[°C]	-10...100
Protection		IP 68

Mechanical data

Weight	[g]	874.979
Dimensions	[mm]	15 x 15 x 47
Molded-body material		PVC
Material nut		stainless steel (1.4571/316Ti)

Remarks


Pack quantity		1 pcs.
---------------	--	--------

Electrical connection


Cable: 25 m, PVC, yellow; 3 x 0.34 mm² / AWG 22

Electrical connection - Socket

 Connector: 1 x 1/2", straight; coding: C; Contacts: 3, gold-plated; Moulded body: PVC; Locking: stainless steel (1.4571/316Ti)



Connection

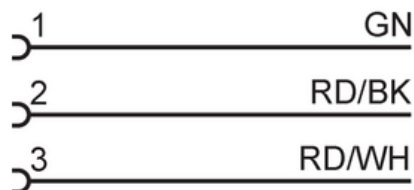

Core colors :
 GN = green
 RD/BK = red/black
 RD/WH = red/white