


E18210



Female cordset

ADOAA030VAS0010E03

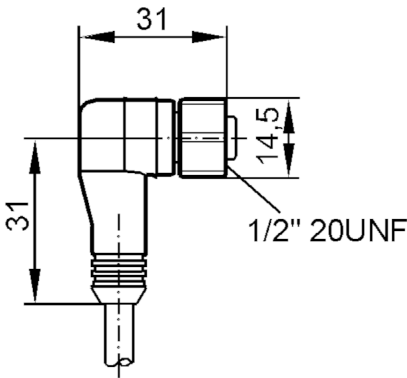

Application		
System		gold-plated contacts
Electrical data		
Operating voltage	[V]	< 300 AC/DC
Operating conditions		
Ambient temperature	[°C]	-10...100
Protection		IP 68
Mechanical data		
Weight	[g]	294.835
Dimensions	[mm]	31 x 14.5 x 31
Material		PVC
Molded-body material		PVC
Material nut		stainless steel (1.4571/316Ti)
Remarks		
Pack quantity		1 pcs.

E18210



Female cordset

ADOAA030VAS0010E03

Electrical connection


Cable: 10 m, PVC, yellow; 3 x 0.34 mm² / AWG 22

Electrical connection - Socket

Connector: 1 x 1/2", angled; coding: C; Moulded body: PVC; Locking: stainless steel (1.4571/316Ti); Contacts: gold-plated



Connection

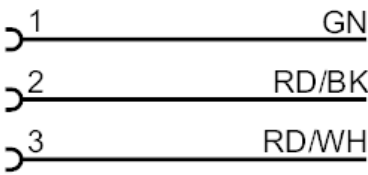

GN =
RD/BK =
RD/WH =

Core colors :
green
red/black
red/white