


# E18212



## Female cordset

ADOGA030MSS0002E03

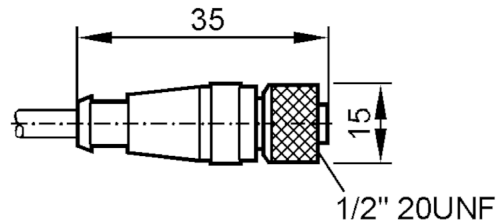

### Application

Special feature	gold-plated contacts
Application	Industrial applications

### Electrical data

Operating voltage [V]	< 300 AC/DC
-----------------------	-------------

### Operating conditions

Ambient temperature [°C]	-20...80
Protection	IP 68

### Mechanical data

Weight [g]	63.503
Dimensions [mm]	15 x 15 x 35
Molded-body material	PVC
Material nut	brass, nickel-plated

### Remarks

 
Pack quantity	1 pcs.
---------------	--------

### Electrical connection

Cable: 2 m, PVC, yellow; 3 x 0.34 mm<sup>2</sup> / AWG 22

### Electrical connection - Socket

Connector: 1 x 1/2", straight; coding: C; Contacts: 3, gold-plated; Moulded body: PVC; Locking: brass, nickel-plated




# E18212



## Female cordset

ADOGA030MSS0002E03

### Connection

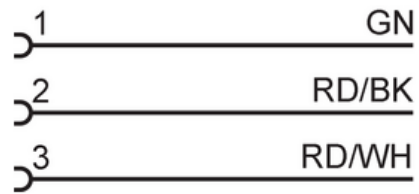

GN = green  
RD/BK = red/black  
RD/WH = red/white