


E18213



Female cordset

ADOGA030MSS0005E03

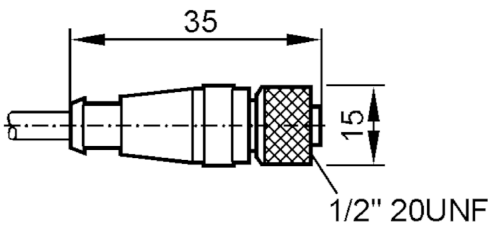

Application		
System		gold-plated contacts
Electrical data		
Operating voltage	[V]	< 300 AC/DC
Operating conditions		
Ambient temperature	[°C]	-20...80
Protection		IP 68
Mechanical data		
Weight	[g]	154.221
Dimensions	[mm]	15 x 15 x 35
Material		PVC
Molded-body material		PVC
Material nut		brass, nickel-plated
Remarks		
Pack quantity		1 pcs.

E18213



Female cordset

ADOGA030MSS0005E03

Electrical connection


Cable: 5 m, PVC, yellow; 3 x 0.34 mm² / AWG 22

Electrical connection - Socket

Connector: 1 x 1/2", straight; coding: C; Moulded body: PVC; Locking: brass, nickel-plated; Contacts: gold-plated



Connection

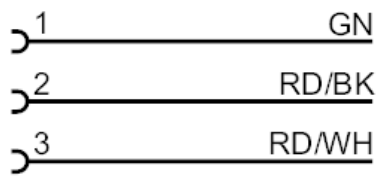

GN =
RD/BK =
RD/WH =

Core colors :
green
red/black
red/white