


E18242



Female cordset

ADOGA050MSS0010A05

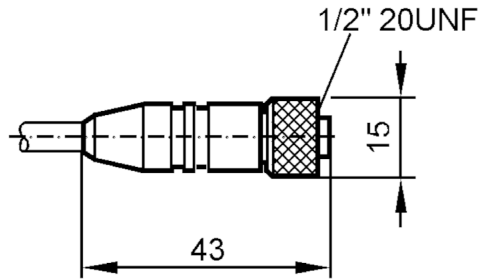

Application

Application: Industrial applications

Electrical data

Operating voltage [V]: < 250 AC/DC
 Max. current load total [A]: 4

Operating conditions

Ambient temperature [°C]: -40...90
 Protection: IP 68

Mechanical data

Weight [g]: 430.912
 Material: TPU (urethane)
 Molded-body material: TPU (urethane)
 Material nut: brass, nickel-plated

Remarks

Pack quantity: 1 pcs.

Electrical connection

Cable: 10 m, PVC, black, Ø 5.3 mm; 5 x 0.34 mm² (19 x Ø 0.16 mm) / AWG 22

Electrical connection - Socket

Connector: 1 x 1/2", straight; coding: C; Contacts: 5; Moulded body: TPU (urethane); Locking: brass, nickel-plated




E18242



Female cordset

ADOGA050MSS0010A05

Connection

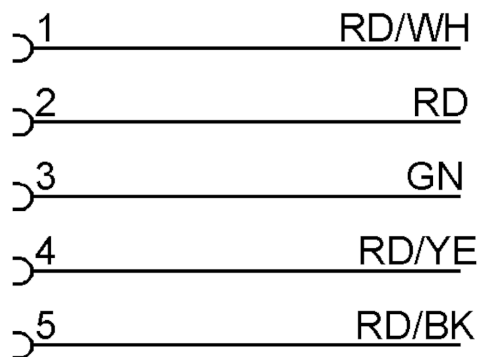

Core colors :
BK = black
GN = green
RD = red
WH = white
YE = yellow