


# E18343



## Wirable plug

 
SSTGH080MSSFKPG

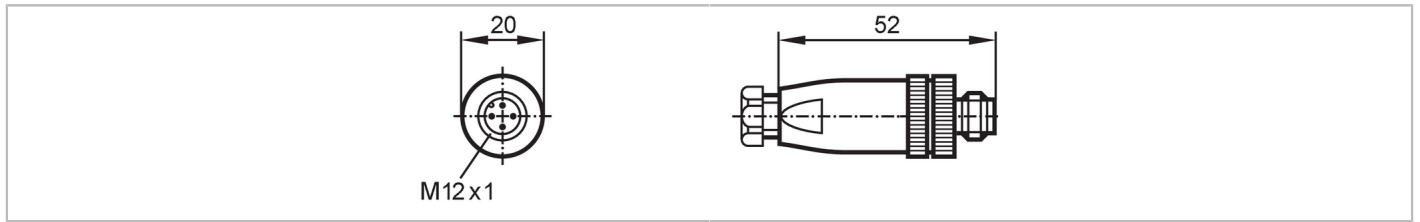

| Application                 |  |
|-----------------------------|--|
| Special feature             | Free from silicone; gold-plated contacts |
| Application                 | Industrial applications                  |
| Free from silicone          | yes                                      |
| Electrical data             |  |
| Operating voltage [V]       | < 125 AC/DC                              |
| Max. current load total [A] | 4; (...40 °C)                            |
| Operating conditions        |  |
| Ambient temperature [°C]    | -25...100                                |
| Protection                  | IP 68                                    |
| Mechanical data             |  |
| Weight [g]                  | 23                                       |
| Dimensions [mm]             | 20 x 20 x 52                             |
| Molded-body material        | PA                                       |
| Material nut                | brass, nickel-plated                     |
| Remarks                     |  |
| Pack quantity               | 1 pcs.                                   |

**Electrical connection**  
terminals: ...0.75 mm<sup>2</sup>; Cable sheath: Ø 6...8 mm

**Electrical connection - plug**  
Connector: 1 x M12, straight; coding: A; Contacts: 8, gold-plated; Moulded body: PA; Locking: brass, nickel-plated



# E18343



## Wirable plug

SSTGH080MSSFKPG

### Connection

|   |    |
|---|----|
| 1 | WH |
| 2 | BN |
| 3 | GN |
| 4 | YE |
| 5 | GY |
| 6 | PK |
| 7 | BU |
| 8 | RD |