


E19902



Y/T splitter

ZDO2H045MSS0010B05

Article no longer available - archive entry

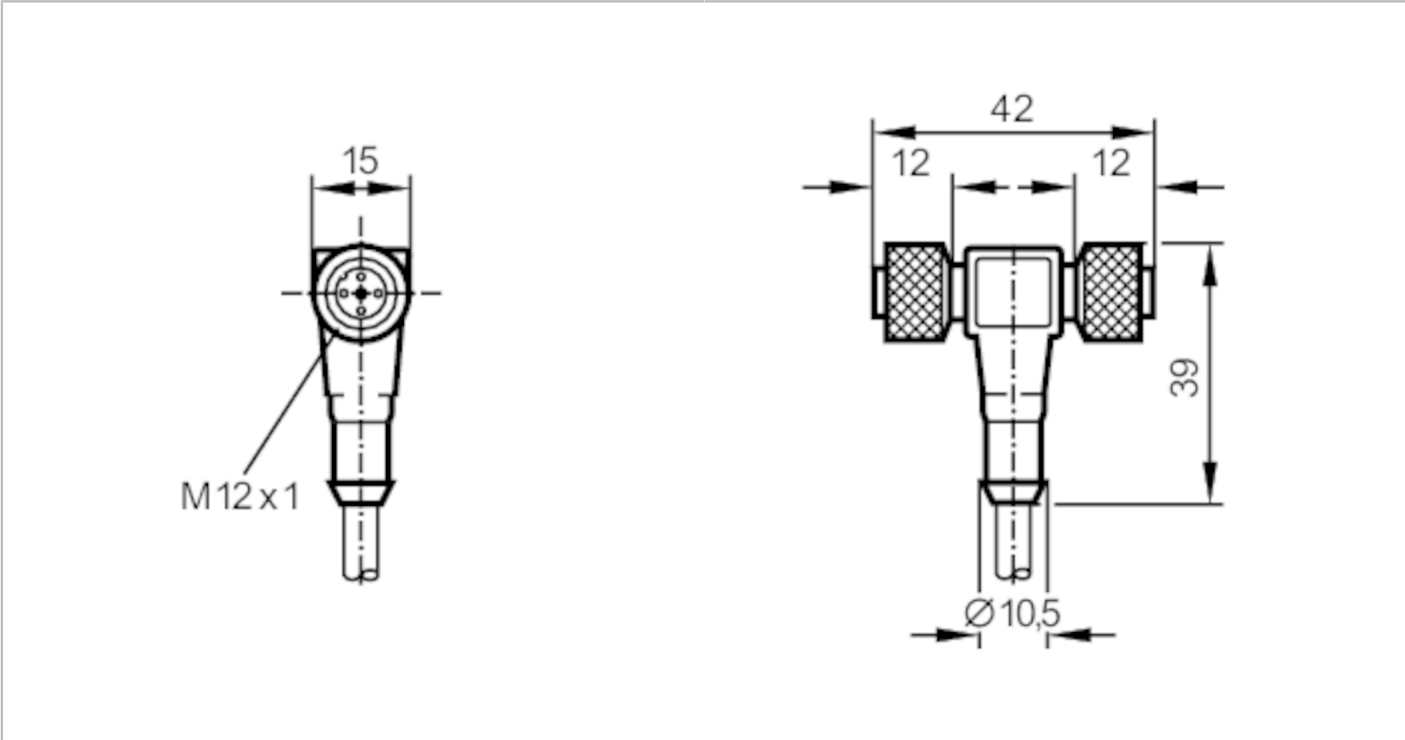

Electrical data		
Operating voltage	[V]	< 125 AC / < 150 DC
Max. current load per module/slot	[A]	4
Max. current load total	[A]	4
Operating conditions		
Ambient temperature	[°C]	-15...90
Protection		IP 67
Mechanical data		
Material		TPU (urethane)
Remarks		
Pack quantity		1 pcs.

E19902




Y/T splitter

ZDO2H045MSS0010B05

Electrical connection

Cable: 10 m, PUR / PVC, orange, Ø 5 mm; 4 x 0.25 mm² (32 x Ø 0.1 mm)

Connection

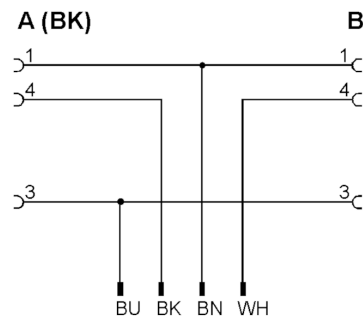

Core colors :
BK = black
BN = brown
BU = blue
WH = white