

E20405



Female cordset

ADOAH042MSS0005A04

Article no longer available - archive entry



Electrical data		
Operating voltage	[V]	10...30 DC
Outputs		
Electrical design		PNP
Operating conditions		
Ambient temperature	[°C]	-25...90
Protection		IP 67
Mechanical data		
Dimensions	[mm]	27 x 15 x 39
Material		TPU (urethane) transparent
Molded-body material		TPU (urethane), transparent
Material nut		brass, nickel-plated
Displays / operating elements		
Display	Switching status	1 x LED, yellow
	Power	1 x LED, green
Remarks		
Pack quantity		1 pcs.

E20405



Female cordset

ADOAH042MSS0005A04

Electrical connection


Cable: 5 m, PUR / PVC, orange, Ø 5 mm; 4 x 0.25 mm² (32 x Ø 0.1 mm)

Electrical connection - Socket

Connector: 1 x M12, angled; coding: A; Moulded body: TPU (urethane), transparent; Locking: brass, nickel-plated; Tightening torque: 0.5 Nm



Connection

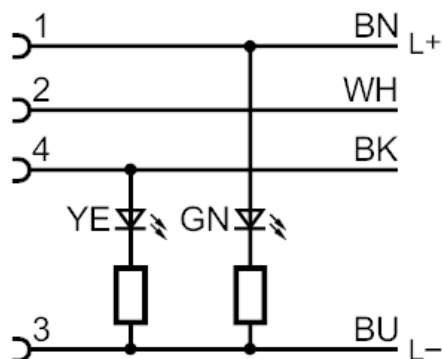

Core colors :
BN = brown
BK = black
BU = blue
WH = white