

E20407




Fiber optic diffuse reflection sensor

FT-00-P-A-R4/0,12M

Article no longer available - archive entry

Alternative articles: E20569
When selecting an alternative article and accessories please note that technical data may differ!

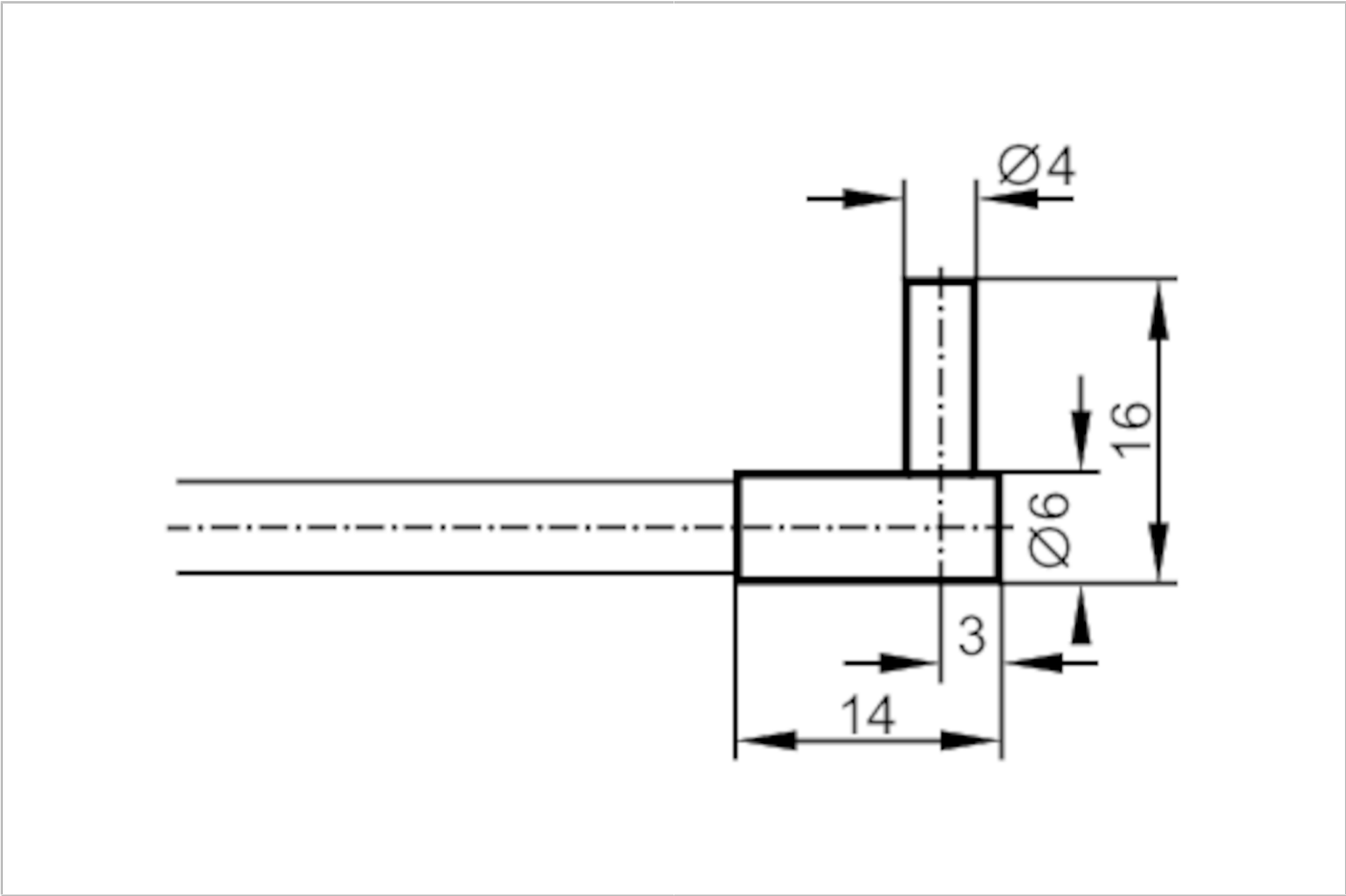

Application	
Function principle	Diffuse reflection sensor
Monitoring range	
Range with fiber optic amplifier type	OKF; OUF
OKF	
Range fiber optics [mm]	40
OUF	
Range fiber optics [mm]	40
Operating conditions	
Ambient temperature [°C]	-20...80
Mechanical data	
Version of sensing head	angled
Sensing head diameter [mm]	4
Sensing head length [mm]	10
Total length [mm]	120

E20407



Fiber optic diffuse reflection sensor

FT-00-P-A-R4/0,12M

Min. bending radius	[mm]	20
Material	Adapter: PPE	
Fiber material	glass	
Fiber head material	aluminum	
Fiber sheath material	PVC	
Remarks		
Pack quantity	1 pcs.	