


E20429



Female cordset

AD0GB030ZDS0005E03

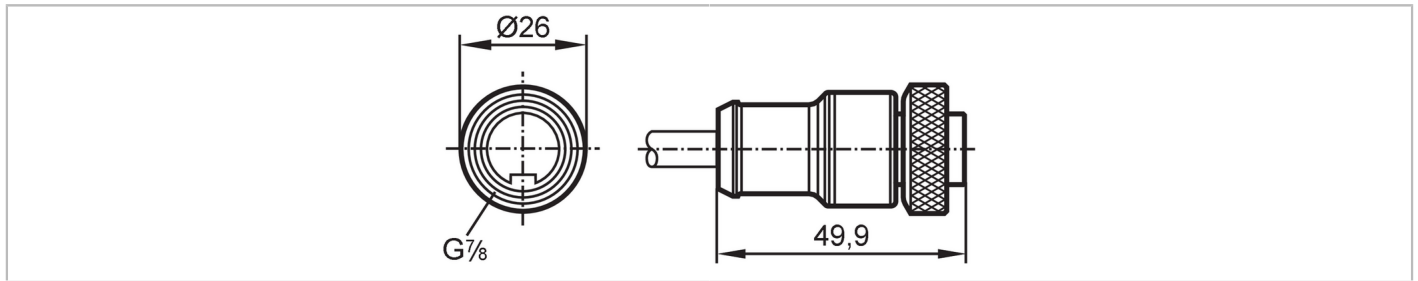

Application

Application	Industrial applications
-------------	-------------------------

Electrical data

Operating voltage	[V]	< 300 AC/DC
-------------------	-----	-------------

Operating conditions

Ambient temperature	[°C]	-30...80
Ambient temperature (moving)	[°C]	-5...80
Protection		IP 68

Mechanical data

Weight	[g]	279.3
Dimensions	[mm]	26 x 26 x 49.9
Molded-body material		TPU (urethane)
Material nut		diecast zinc

Remarks

Pack quantity		1 pcs.
---------------	--	--------

Electrical connection


Cable: 5 m, PVC, black, Ø 5.2 mm; 3 x 0.75 mm² (24 x Ø 0.2 mm)

Electrical connection - Socket

Connector: 1 x 7/8", straight; Contacts: 3; Moulded body: TPU (urethane); Locking: diecast zinc



Connection

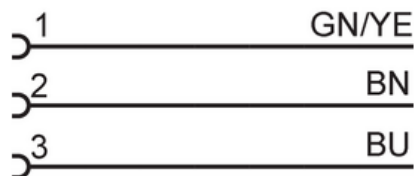

Core colors :
 BN = brown
 BU = blue
 GN/YE = green/yellow