




Fiber optic diffuse reflection sensor

FT-00-A-V-E1/0,35m

Article no longer available - archive entry

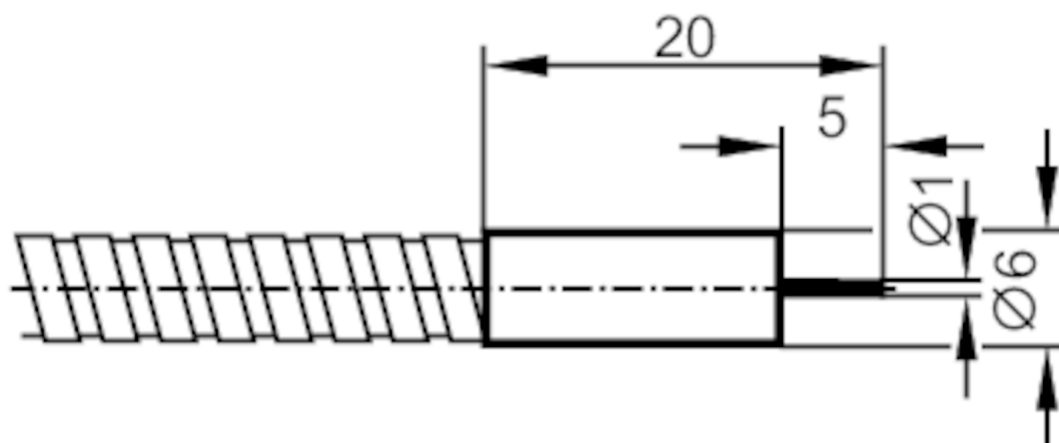

Application

Function principle

Diffuse reflection sensor

Monitoring range

Range with fiber optic amplifier type

OKF; OUF

OKF

Range fiber optics

[mm]

8

OUF

Range fiber optics

[mm]

8

Operating conditions

Ambient temperature

[°C]

-40...290

Mechanical data

Version of sensing head

straight

Sensing head diameter

[mm]

1

Sensing head length

[mm]

5

Total length

[mm]

350; (+5 mm)

Min. bending radius

[mm]

20

Material

Adapter: ABS

Fiber material

glass

E20435



Fiber optic diffuse reflection sensor

FT-00-A-V-E1/0,35m

Fiber head material	stainless steel (1.4305 / 303)
Fiber sheath material	aluminum
Remarks	
Pack quantity	1 pcs.