

E20439




Fiber optic diffuse reflection sensor

FT-30-A-A-E6/1,5m

Article no longer available - archive entry

Alternative articles: E20290
When selecting an alternative article and accessories please note that technical data may differ!

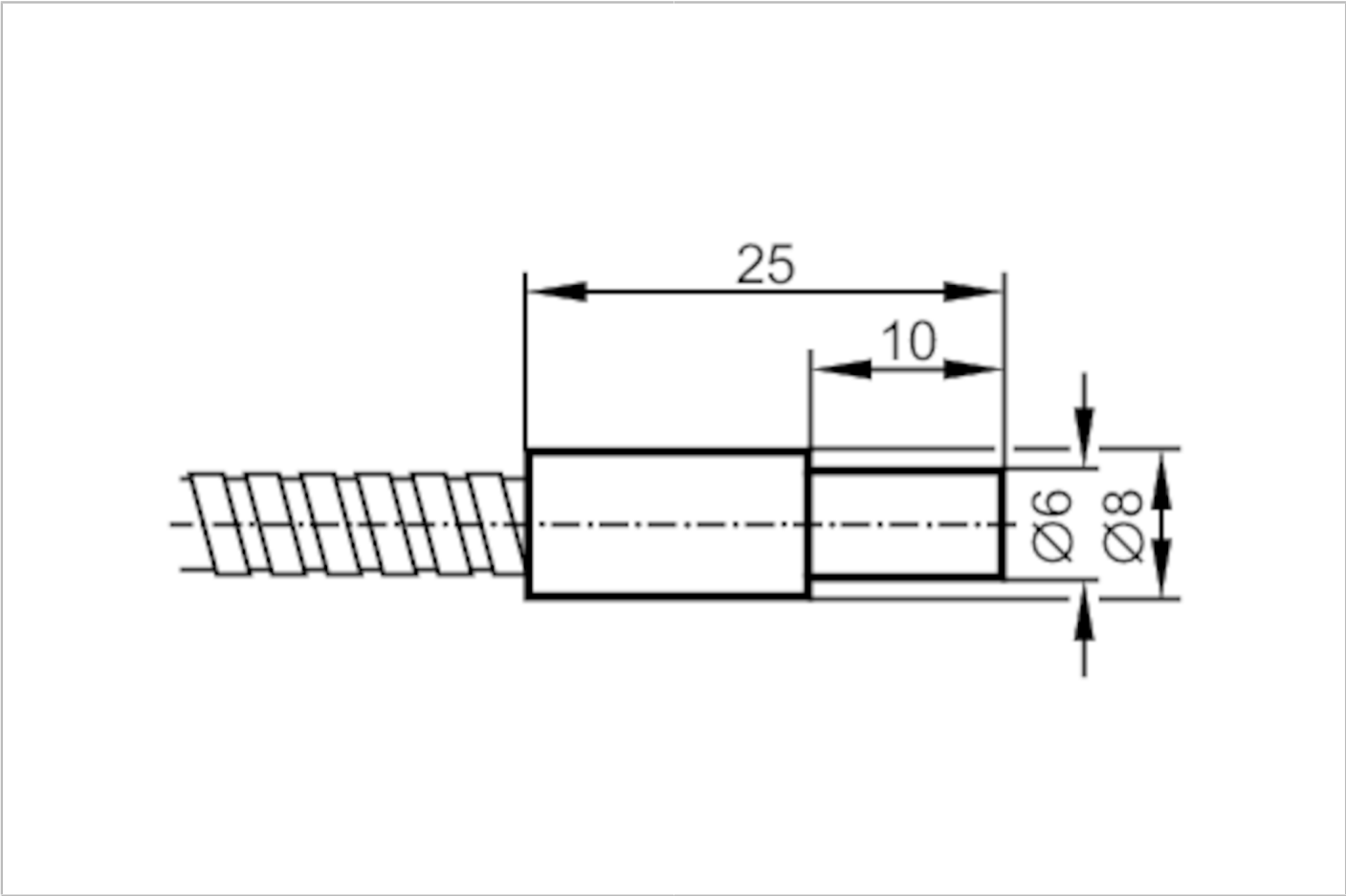

Application	
Function principle	Diffuse reflection sensor
Monitoring range	
Range with fiber optic amplifier type	OIF
OIF	
Range fiber optics [mm]	36
Operating conditions	
Ambient temperature [°C]	-40...290
Mechanical data	
Version of sensing head	straight
Sensing head diameter [mm]	6
Total length [mm]	1500
Min. bending radius [mm]	30
Material	Adapter: PA
Fiber material	glass
Fiber head material	aluminum

E20439



Fiber optic diffuse reflection sensor

FT-30-A-A-E6/1,5m

Fiber sheath material	aluminum
Remarks	
Pack quantity	1 pcs.