




Fiber optic through beam sensor

FE-00-P-A-E2,5/0,8M

Article no longer available - archive entry

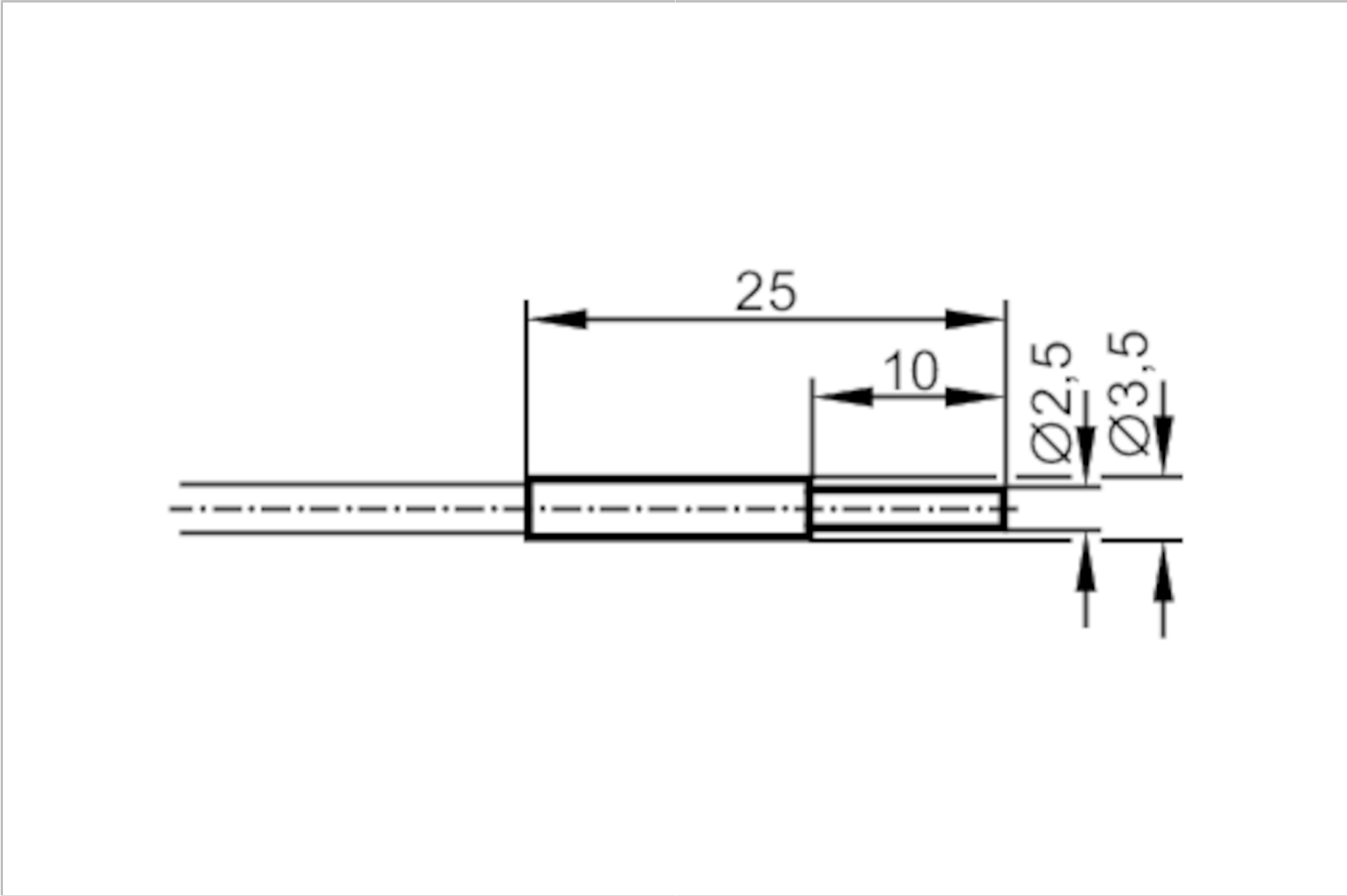

Application		
Function principle		Through-beam sensor
Monitoring range		
Range with fiber optic amplifier type		OKF; OUF
OKF		
Range of fiber optics	[mm]	120
OUF		
Range of fiber optics	[mm]	120
Operating conditions		
Ambient temperature	[°C]	-20...80
Mechanical data		
Version of sensing head		straight
Sensing head diameter	[mm]	2.5
Sensing head length	[mm]	10
Total length	[mm]	800
Min. bending radius	[mm]	10
Material		Adapter: PPE
Fiber material		glass

E20449



Fiber optic through beam sensor

FE-00-P-A-E2,5/0,8M

Fiber head material	aluminum
Fiber sheath material	PVC
Accessories	
Items supplied	E20106
Remarks	
Pack quantity	1 pcs.