

E20470



Female cordset

ADOAH042MSS0010A04

Article no longer available - archive entry



Electrical data

Operating voltage [V] 10...30 DC

Outputs

Electrical design PNP

Operating conditions

Ambient temperature [°C] -25...90

Protection IP 67

Mechanical data

Dimensions [mm] 27 x 15 x 39

Material TPU (urethane) transparent

Molded-body material TPU (urethane), transparent

Material nut brass, nickel-plated

Displays / operating elements

Display Switching status 1 x LED, yellow

Power 1 x LED, green

Remarks

Pack quantity 1 pcs.

E20470



Female cordset

ADOAH042MSS0010A04

Electrical connection


Cable: 10 m, PUR / PVC, orange, Ø 5 mm; 4 x 0.25 mm² (32 x Ø 0.1 mm)

Electrical connection - Socket

Connector: 1 x M12, angled; coding: A; Moulded body: TPU (urethane), transparent; Locking: brass, nickel-plated; Tightening torque: 0.5 Nm



Connection

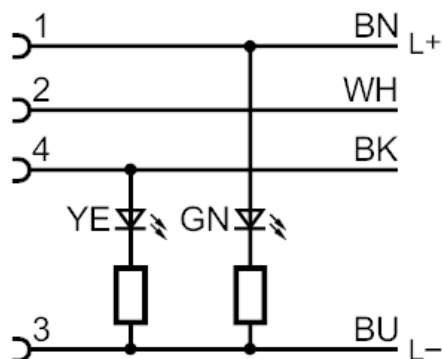

Core colors :
BN = brown
BK = black
BU = blue
WH = white