


E20477



Female cordset

ADOAH043MSS0005E04

Article no longer available - archive entry

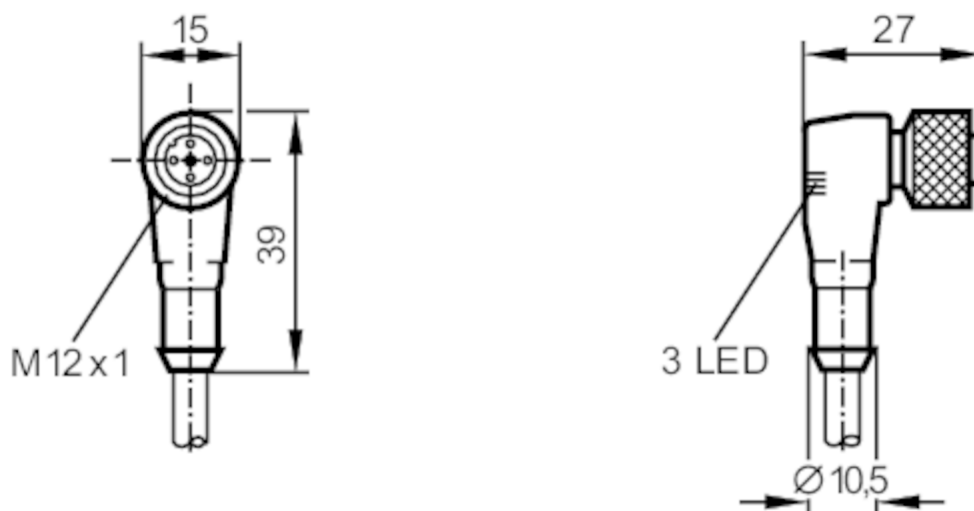

Electrical data

Operating voltage [M] 10...30 DC

Outputs

Electrical design PNP

Operating conditions

Ambient temperature [°C] -25...70

Protection IP 67

Mechanical data

Dimensions [mm] 27 x 15 x 39

Material TPU (urethane) transparent

Molded-body material TPU (urethane), transparent

Material nut brass, nickel-plated

Displays / operating elements

Display	Switching status	2 x LED, yellow
	Power	1 x LED, green

Remarks

Pack quantity 1 pcs.

E20477



Female cordset

ADOAH043MSS0005E04

Electrical connection


Cable: 5 m, PVC, orange, Ø 5 mm; 4 x 0.25 mm² (32 x Ø 0.1 mm)

Electrical connection - Socket

Connector: 1 x M12, angled; coding: A; Moulded body: TPU (urethane), transparent; Locking: brass, nickel-plated



Connection

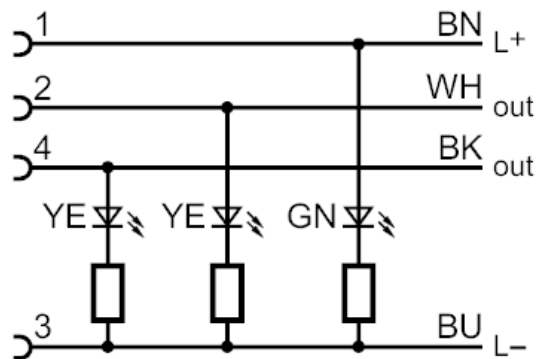

BN =	Core colors :
BK =	brown
BU =	black
WH =	blue
	white