

E20524




Fiber optic diffuse reflection sensor

FT-00-M-V-M6/2m

Article no longer available - archive entry

Alternative articles: E20570
When selecting an alternative article and accessories please note that technical data may differ!

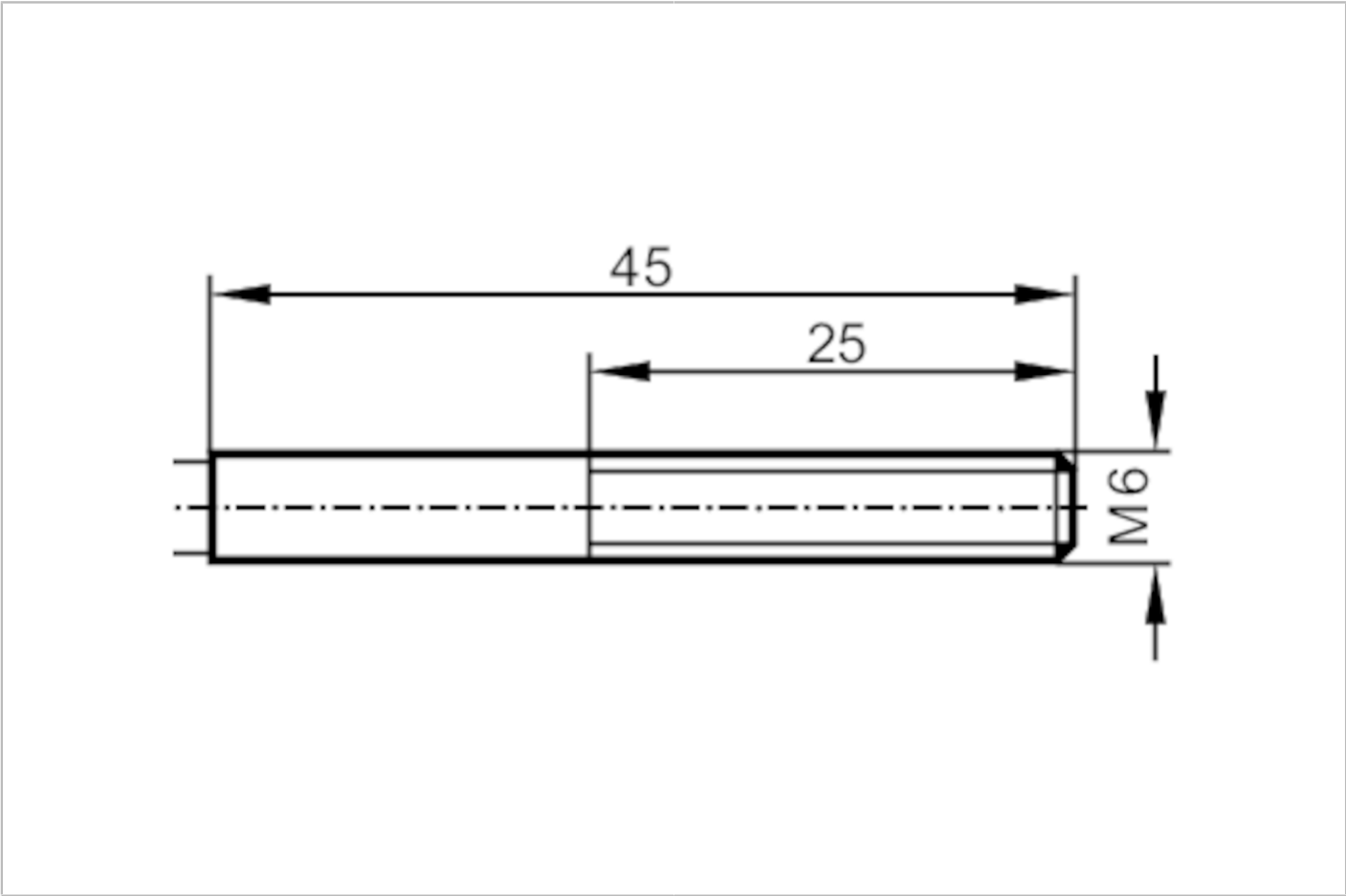

Application	
Function principle	Diffuse reflection sensor
Monitoring range	
Range with fiber optic amplifier type	OKF; OUF
OKF	
Range fiber optics [mm]	32
OUF	
Range fiber optics [mm]	32
Operating conditions	
Ambient temperature [°C]	-20...150
Mechanical data	
Version of sensing head	straight
Sensing head thread	M6
Sensing head length [mm]	45
Total length [mm]	2000

E20524



Fiber optic diffuse reflection sensor

FT-00-M-V-M6/2m

Min. bending radius	[mm]	20
Fiber material		glass
Fiber head material		stainless steel (1.4305 / 303)
Fiber sheath material		metal silicone
Remarks		
Pack quantity		1 pcs.