




## Fiber optic diffuse reflection sensor

FT-00-M-V-E3/2M

Article no longer available - archive entry

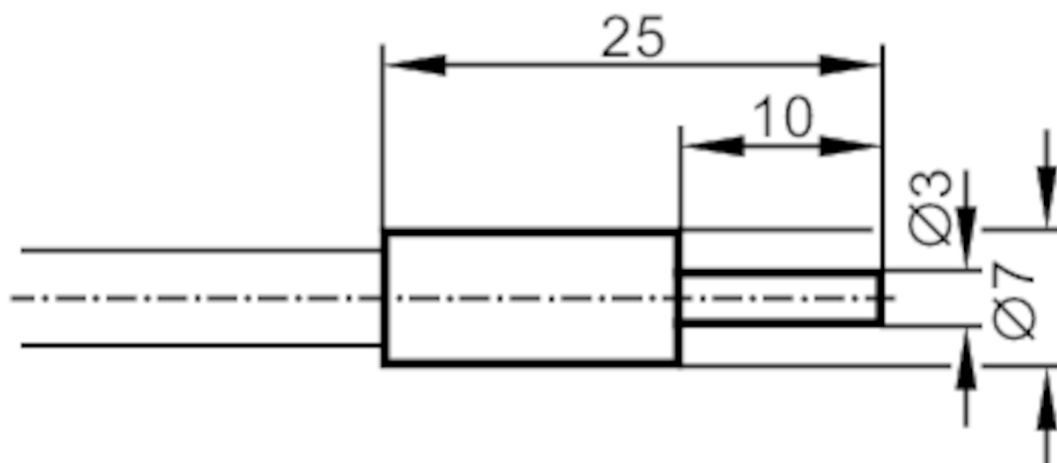

## Application

Function principle

Diffuse reflection sensor

## Monitoring range

Range with fiber optic amplifier type

OKF; OUF

## OKF

Range fiber optics

[mm]

32

## OUF

Range fiber optics

[mm]

32

## Operating conditions

Ambient temperature

[°C]

-20...150

## Mechanical data

Version of sensing head

straight

Sensing head diameter

[mm]

3

Sensing head length

[mm]

10

Total length

[mm]

2000

Min. bending radius

[mm]

20

Fiber material

glass

Fiber head material

stainless steel (1.4305 / 303)

E20527



Fiber optic diffuse reflection sensor

FT-00-M-V-E3/2M

|                       |                |
|-----------------------|----------------|
| Fiber sheath material | metal silicone |
| Remarks               |                |
| Pack quantity         | 1 pcs.         |