




Fiber optic through beam sensor

FE-00-M-V-R3/1,5m

Article no longer available - archive entry

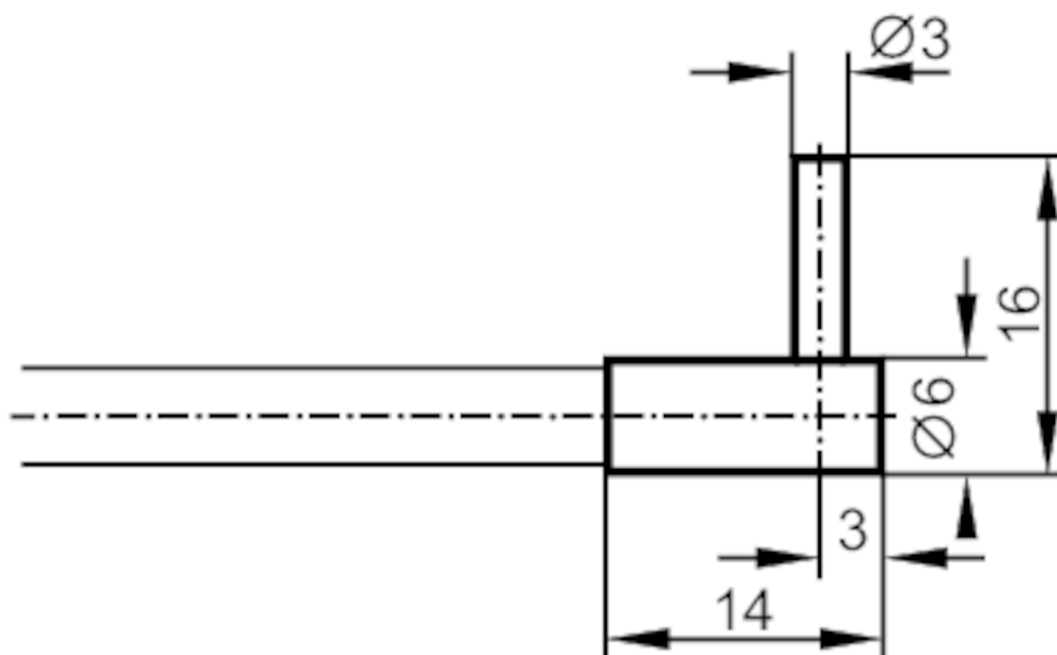

Application

Function principle

Through-beam sensor

Monitoring range

Range with fiber optic amplifier type

OKF; OUF

OKF

Range of fiber optics

[mm]

108

OUF

Range of fiber optics

[mm]

108

Operating conditions

Ambient temperature

[°C]

-20...150

Mechanical data

Version of sensing head

angled

Sensing head diameter

[mm]

3

Sensing head length

[mm]

10

Total length

[mm]

1500

Min. bending radius

[mm]

20

Fiber material

glass

Fiber head material

stainless steel (1.4305 / 303)

E20540



Fiber optic through beam sensor

FE-00-M-V-R3/1,5m

Fiber sheath material	metal silicone
Remarks	
Pack quantity	1 pcs.