




Fiber optic through beam sensor

FE-00-M-V-E1/1,5M

Article no longer available - archive entry

Alternative articles: E20492
When selecting an alternative article and accessories please note that technical data may differ!

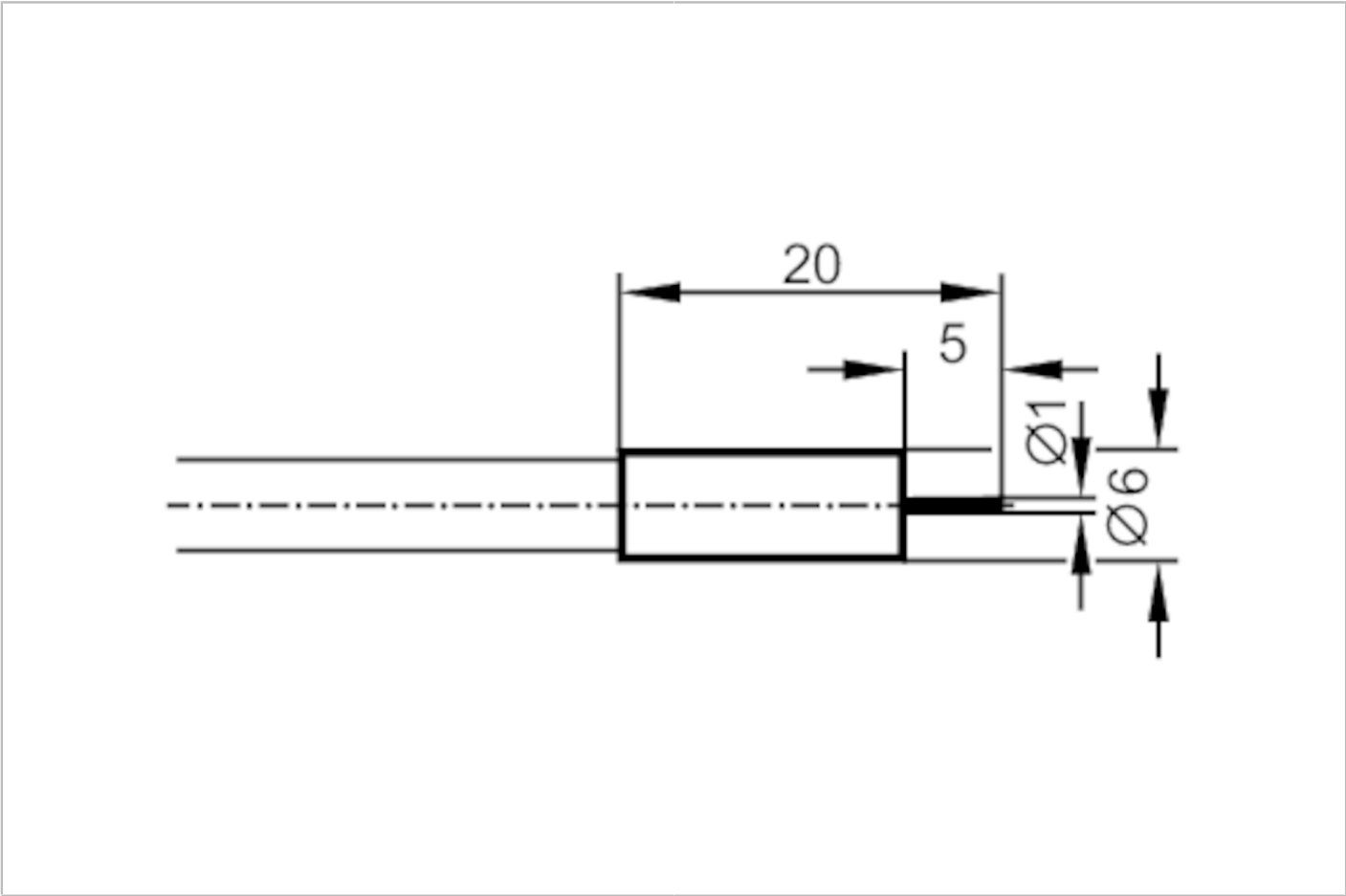

Application	
Function principle	Through-beam sensor
Monitoring range	
Range with fiber optic amplifier type	OKF; OUF
OKF	
Range of fiber optics [mm]	45
OUF	
Range of fiber optics [mm]	45
Operating conditions	
Ambient temperature [°C]	-20...150
Mechanical data	
Version of sensing head	straight
Sensing head diameter [mm]	1
Sensing head length [mm]	5
Total length [mm]	1500

E20547



Fiber optic through beam sensor

FE-00-M-V-E1/1,5M

Min. bending radius	[mm]	20
Fiber material		glass
Fiber head material		stainless steel (1.4305 / 303)
Fiber sheath material		metal silicone
Accessories		
Items supplied		E20103
Remarks		
Pack quantity		1 pcs.