




Fiber optic diffuse reflection sensor

FT-00-P-A-R4/0,14M

Article no longer available - archive entry

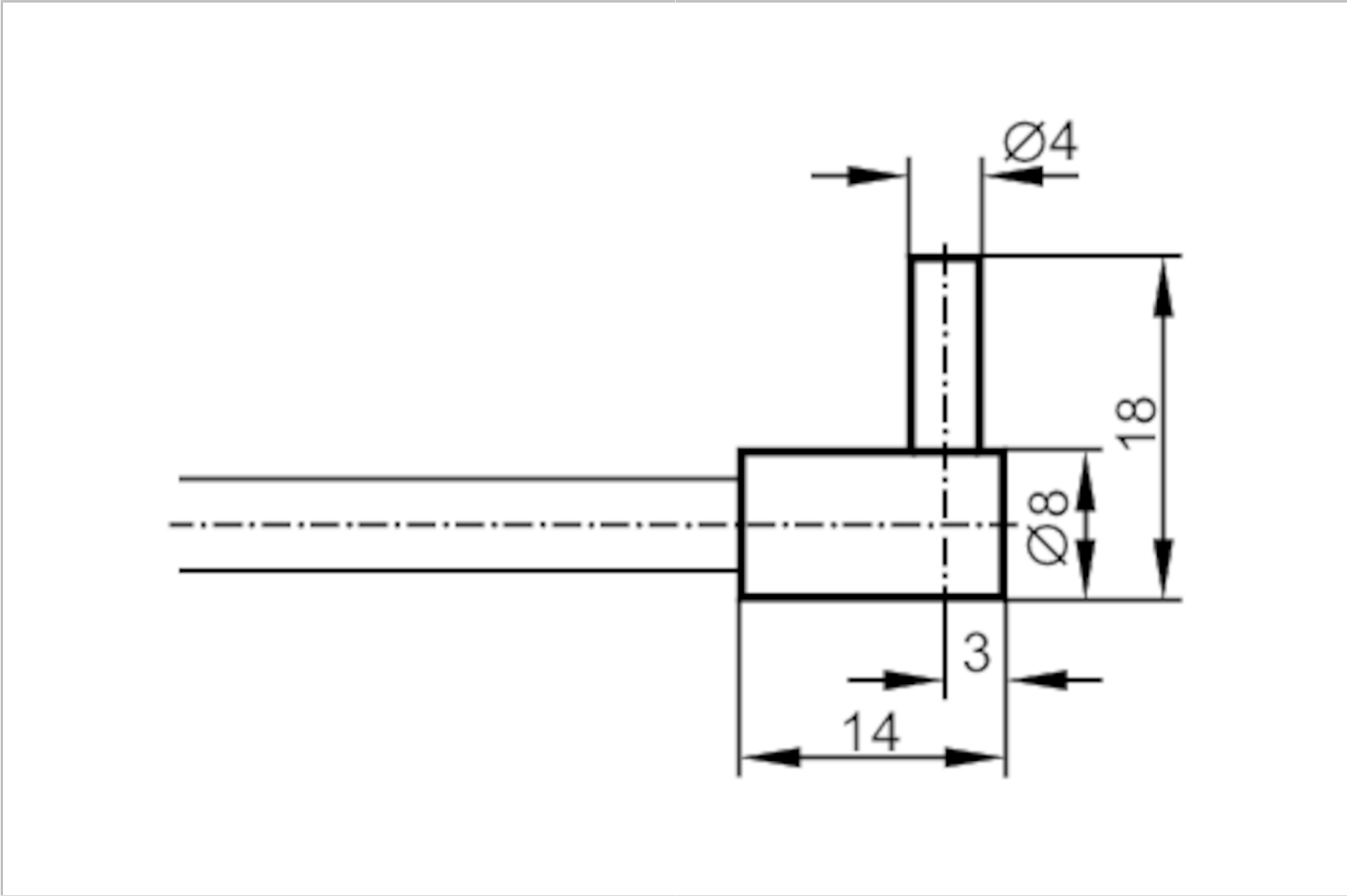

Application		
Function principle		Diffuse reflection sensor
Monitoring range		
Range with fiber optic amplifier type		OKF; OUF
OKF		
Range fiber optics	[mm]	40
OUF		
Range fiber optics	[mm]	40
Operating conditions		
Ambient temperature	[°C]	-20...150
Mechanical data		
Version of sensing head		angled
Sensing head diameter	[mm]	4
Sensing head length	[mm]	10
Total length	[mm]	100; (+10 mm)
Min. bending radius	[mm]	20
Fiber material		glass
Fiber head material		stainless steel (1.4305 / 303)

E20566



Fiber optic diffuse reflection sensor

FT-00-P-A-R4/0,14M

Fiber sheath material	metal silicone
Remarks	
Pack quantity	1 pcs.