




Fiber optic through beam sensor

FE-11-E-A-M3/F1X0,5/0,6M

Article no longer available - archive entry

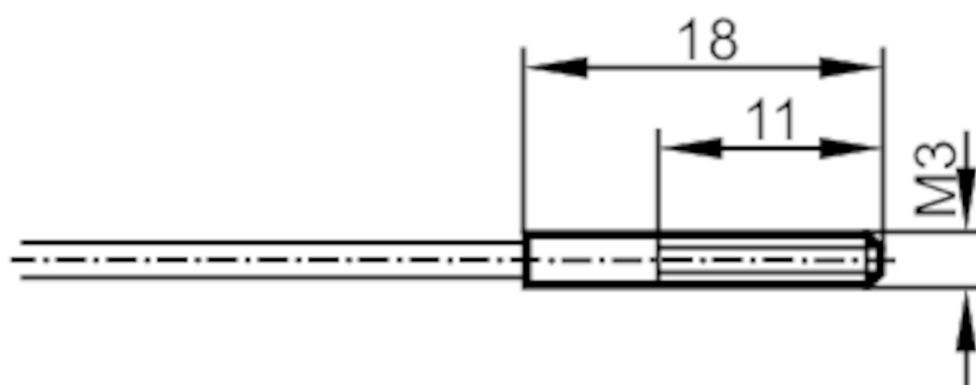

Application

Function principle

Through-beam sensor

Monitoring range

Range with fiber optic
amplifier type

OBF

OBF

Range of fiber optics

[mm]

200

Operating conditions

Ambient temperature

[°C]

-40...70

Mechanical data

Version of sensing head

straight

Sensing head thread

M3

Sensing head length

[mm]

20

Total length

[mm]

600

Min. bending radius

[mm]

30

Fiber material

PMMA

Fiber head material

aluminum

Fiber sheath material

PE

E20607



Fiber optic through beam sensor

FE-11-E-A-M3/F1X0,5/0,6M

Accessories	
Accessories (optional)	Cutter for fibers:, E20600
Remarks	
Pack quantity	1 pcs.