




Fiber optic diffuse reflection sensor

FT-11-E-A-M6/F2x1/1m

Article no longer available - archive entry

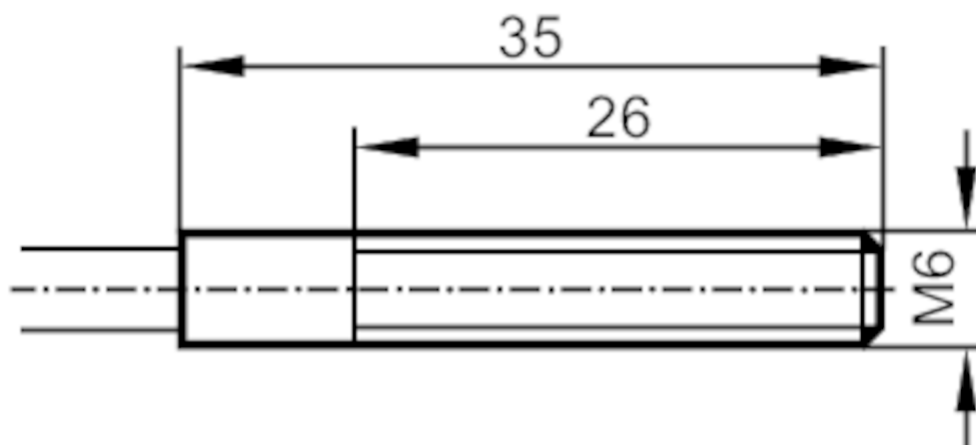

Application

Function principle	Diffuse reflection sensor
--------------------	---------------------------

Monitoring range

Range with fiber optic amplifier type	OBF
---------------------------------------	-----

OBF

Range fiber optics [mm]	70
-------------------------	----

Operating conditions

Ambient temperature [°C]	-40...70
--------------------------	----------

Mechanical data

Version of sensing head	straight
Sensing head thread	M6
Sensing head length [mm]	35
Total length [mm]	1000
Min. bending radius [mm]	30
Fiber material	PMMA
Fiber head material	aluminum
Fiber sheath material	PE

E20632



Fiber optic diffuse reflection sensor

FT-11-E-A-M6/F2x1/1m

Accessories	
Accessories (optional)	Cutter for fibers:, E20600
Remarks	
Pack quantity	1 pcs.