




Fiber optic diffuse reflection sensor

FT-00-M-V-E1/2,5M

Article no longer available - archive entry

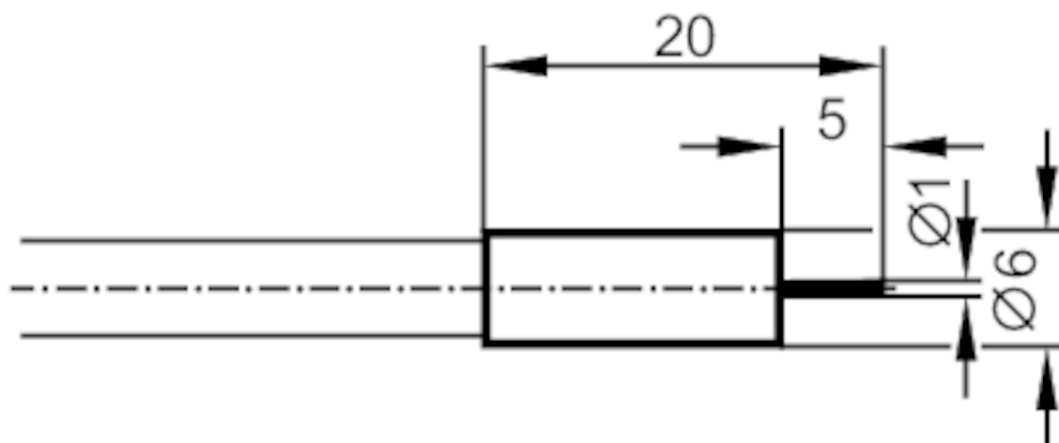

Application

Function principle

Diffuse reflection sensor

Monitoring range

Range with fiber optic
amplifier type

OKF; OUF

OKF

Range fiber optics

[mm]

6

OUF

Range fiber optics

[mm]

6

Operating conditions

Ambient temperature

[°C]

-20...150

Mechanical data

Version of sensing head

straight

Sensing head diameter

[mm]

1

Sensing head length

[mm]

5

Total length

[mm]

2500

Min. bending radius

[mm]

20

Fiber material

glass

Fiber head material

stainless steel (1.4305 / 303)

E20698



Fiber optic diffuse reflection sensor

FT-00-M-V-E1/2,5M

Fiber sheath material	metal silicone
Remarks	
Pack quantity	1 pcs.