


E20711



Fiber optic diffuse reflection sensor

FT-11-EPV-E3/F2X0,5/2M

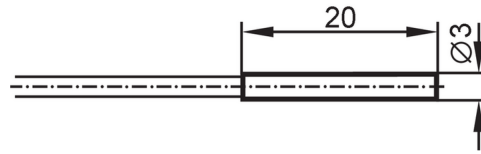

Application	
Function principle	Diffuse reflection sensor
Application	Small bending radius
Monitoring range	
Range with fiber optic amplifier type	OB50; OBF; OCF; OO50
OB50	
Range fiber optics [mm]	20
OBF	
Range fiber optics [mm]	25
OCF (High Power)	
Range fiber optics [mm]	340
OO50	
Range fiber optics [mm]	60
Operating conditions	
Ambient temperature [°C]	-40...70
Mechanical data	
Weight [g]	39.5
Version of sensing head	straight
Sensing head diameter [mm]	3
Sensing head length [mm]	20
Total length [mm]	2000
Min. bending radius [mm]	10
Fiber arrangement	⊙
Core diameter [mm]	2 x 0.5
Fiber material	PMMA
Fiber head material	stainless steel (1.4305 / 303)
Fiber sheath material	PE
Accessories	
Items supplied	Adapter: 1 x OCF
Accessories (optional)	Cutter for fibers:, E20600
Remarks	
Pack quantity	1 pcs.