


E20738



Female cordset

ADOGH080MSS0002B08

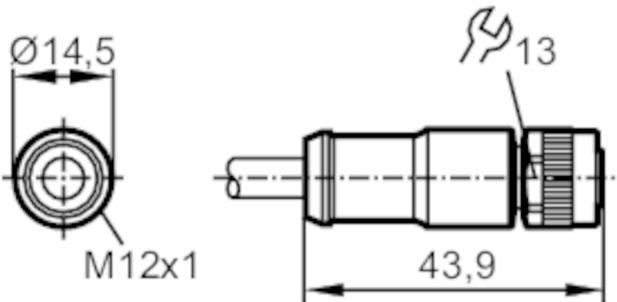

Application		
System		screened cable
Electrical data		
Operating voltage	[V]	< 60 AC/DC
Operating conditions		
Ambient temperature	[°C]	-25...85
Protection		IP 67
Mechanical data		
Weight	[g]	125.5
Dimensions	[mm]	14.5 x 14.5 x 43.9
Material		TPU (urethane)
Molded-body material		TPU (urethane)
Material nut		diecast zinc, nickel-plated
Remarks		
Pack quantity		1 pcs.

E20738



Female cordset


ADOGH080MSS0002B08

Electrical connection

Cable: 2 m, PUR, black, screened; 7 x 0.25 mm² (14 x Ø 0.15 mm)

Electrical connection - Socket

Connector: 1 x M12, straight; coding: A; Moulded body: TPU (urethane); Locking: diecast zinc, nickel-plated

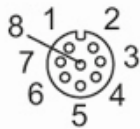

Connection

1	WH
2	BN
3	GN
4	YE
5	GY
6	PK
7	BU
8	screen

Colors to DIN 47100

BN =	brown
BU =	blue
GN =	green
GY =	grey
PK =	pink
WH =	white
YE =	yellow
screen =	screen