




Fiber optic diffuse reflection sensor

FT-18-A-A-M6/1M

Article no longer available - archive entry

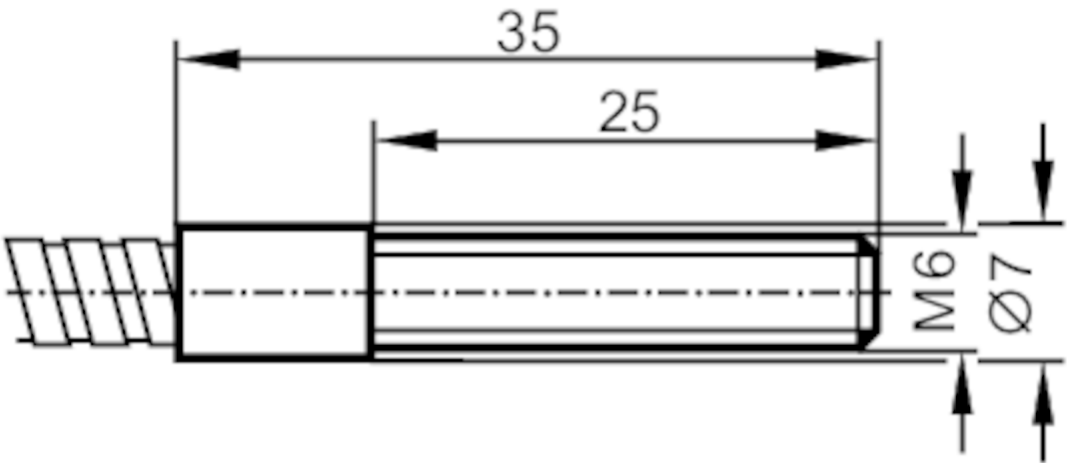

Application	
Function principle	Diffuse reflection sensor
Monitoring range	
Range with fiber optic amplifier type	OGF
OGF	
Range fiber optics [mm]	15
Operating conditions	
Ambient temperature [°C]	-40...290
Mechanical data	
Version of sensing head	straight
Sensing head thread	M6
Sensing head length [mm]	25
Total length [mm]	1000
Min. bending radius [mm]	20
Material	Adapter: PPE
Fiber material	glass
Fiber head material	aluminum
Fiber sheath material	PVC

E20742



Fiber optic diffuse reflection sensor

FT-18-A-A-M6/1M

Remarks	
Pack quantity	1 pcs.