

E20746




Female cordset

ADOAH043MSS0002F04

Article no longer available - archive entry

Alternative articles: E10912

When selecting an alternative article and accessories please note that technical data may differ!

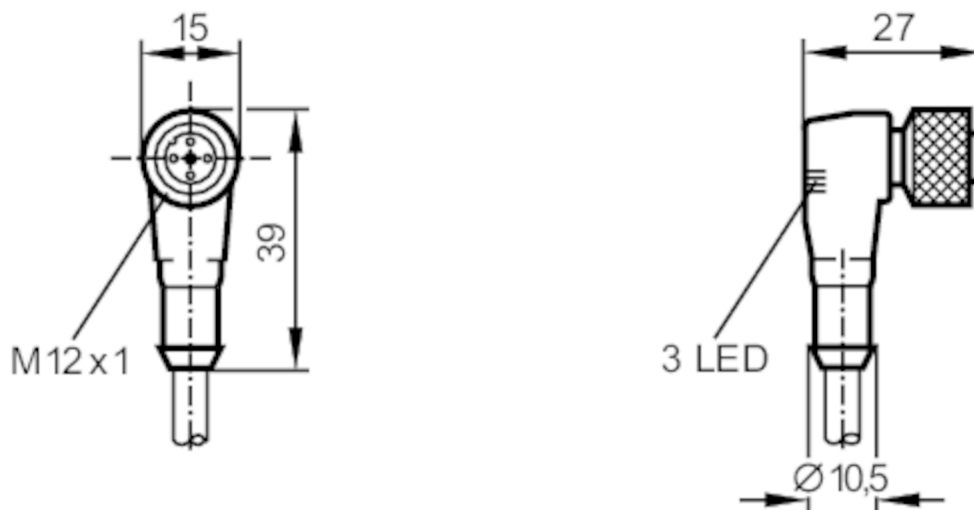

Electrical data

Operating voltage [V] 10...30 DC

Outputs

Electrical design PNP

Operating conditions

Ambient temperature [°C] -25...90

Protection IP 67

Mechanical data

Dimensions [mm] 27 x 15 x 39

Material TPU (urethane) transparent

Molded-body material TPU (urethane), transparent

Material nut brass, weld coated

Displays / operating elements

Display	Switching status	2 x LED, yellow
	Power	1 x LED, green

Remarks

Pack quantity 1 pcs.

E20746



Female cordset

ADOAH043MSS0002F04

Electrical connection


Cable: 2 m, PVC, orange, Ø 4.8 mm; cross-linked; 3 x 0.34 mm² (19 x Ø 0.15 mm)

Electrical connection - Socket

Connector: 1 x M12, angled; coding: A; Moulded body: TPU (urethane), transparent; Locking: brass, weld coated



Connection

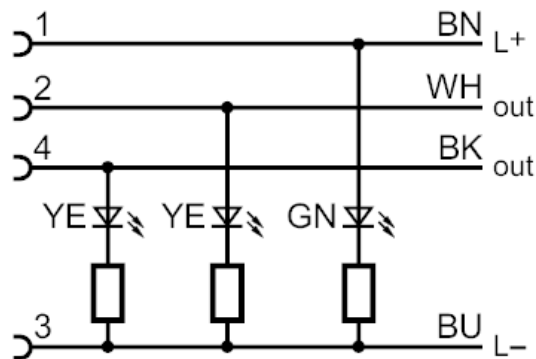

BK =	Core colors :
BN =	black
BU =	brown
WH =	blue
	white