




Fiber optic diffuse reflection sensor

FT-00-P-A-E3

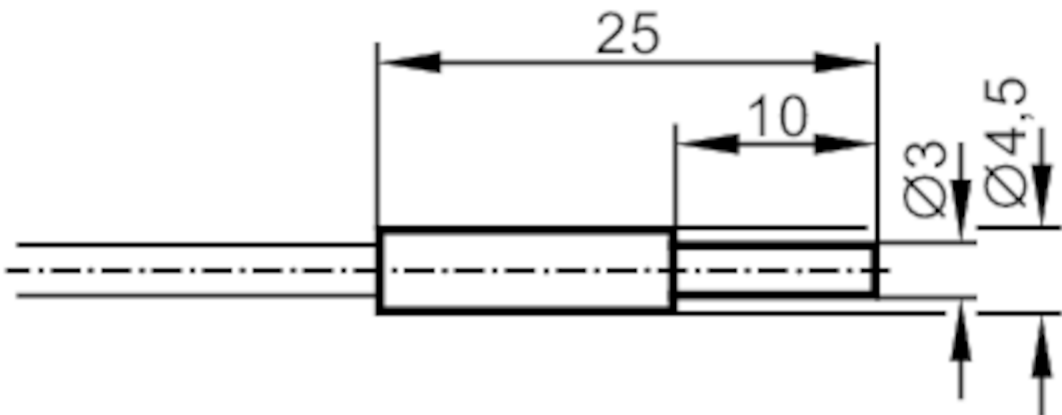

Application		
Function principle		Diffuse reflection sensor
Application		For use in industrial environments
Monitoring range		
Range with fiber optic amplifier type		OKF; OUF; OOF
OKF		
Range fiber optics	[mm]	40
OOF		
Range fiber optics	[mm]	200
OUF		
Range fiber optics	[mm]	40
Operating conditions		
Ambient temperature	[°C]	-20...80
Mechanical data		
Weight	[g]	46
Version of sensing head		straight
Sensing head diameter	[mm]	3
Sensing head length	[mm]	25
Total length	[mm]	600

E20052



Fiber optic diffuse reflection sensor

FT-00-P-A-E3

Min. bending radius	[mm]	20
Fiber arrangement		
Material		Adapter: PPE
Fiber material		glass
Fiber head material		aluminum
Fiber sheath material		PVC
Accessories		
Items supplied		E20105
Remarks		
Pack quantity		1 pcs.