


E20058



Fiber optic diffuse reflection sensor

FT-00-A-A-R4

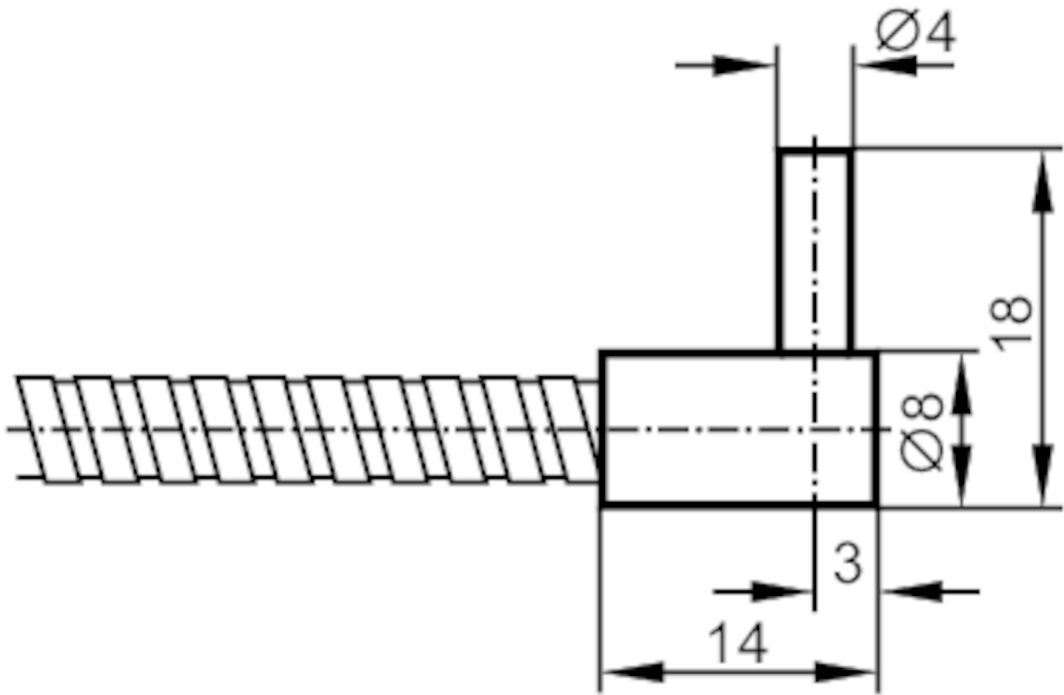

Application		
Function principle		Diffuse reflection sensor
Application		For use in industrial environments; Robust design for use in harsh industrial environments
Monitoring range		
Range with fiber optic amplifier type		OCF; OKF; OOF; OUF
OCF (High Power)		
Range fiber optics	[mm]	290
OKF		
Range fiber optics	[mm]	40
OOF		
Range fiber optics	[mm]	200
OUF		
Range fiber optics	[mm]	40
Operating conditions		
Ambient temperature	[°C]	-40...290
Mechanical data		
Weight	[g]	51.5
Version of sensing head		angled
Sensing head diameter	[mm]	4

E20058



Fiber optic diffuse reflection sensor

FT-00-A-A-R4

Sensing head length	[mm]	10
Total length	[mm]	600
Min. bending radius	[mm]	20; (for fixed installation)
Fiber arrangement		①
Material		Adapter: ABS
Fiber material		glass
Fiber head material		aluminum
Fiber sheath material		aluminum

Accessories

Items supplied	Mounting clamp:, E10221
----------------	-------------------------

Remarks

Pack quantity	1 pcs.
---------------	--------