




Fiber optic diffuse reflection sensor

FT-00-A-A-R4/1M

Article no longer available - archive entry

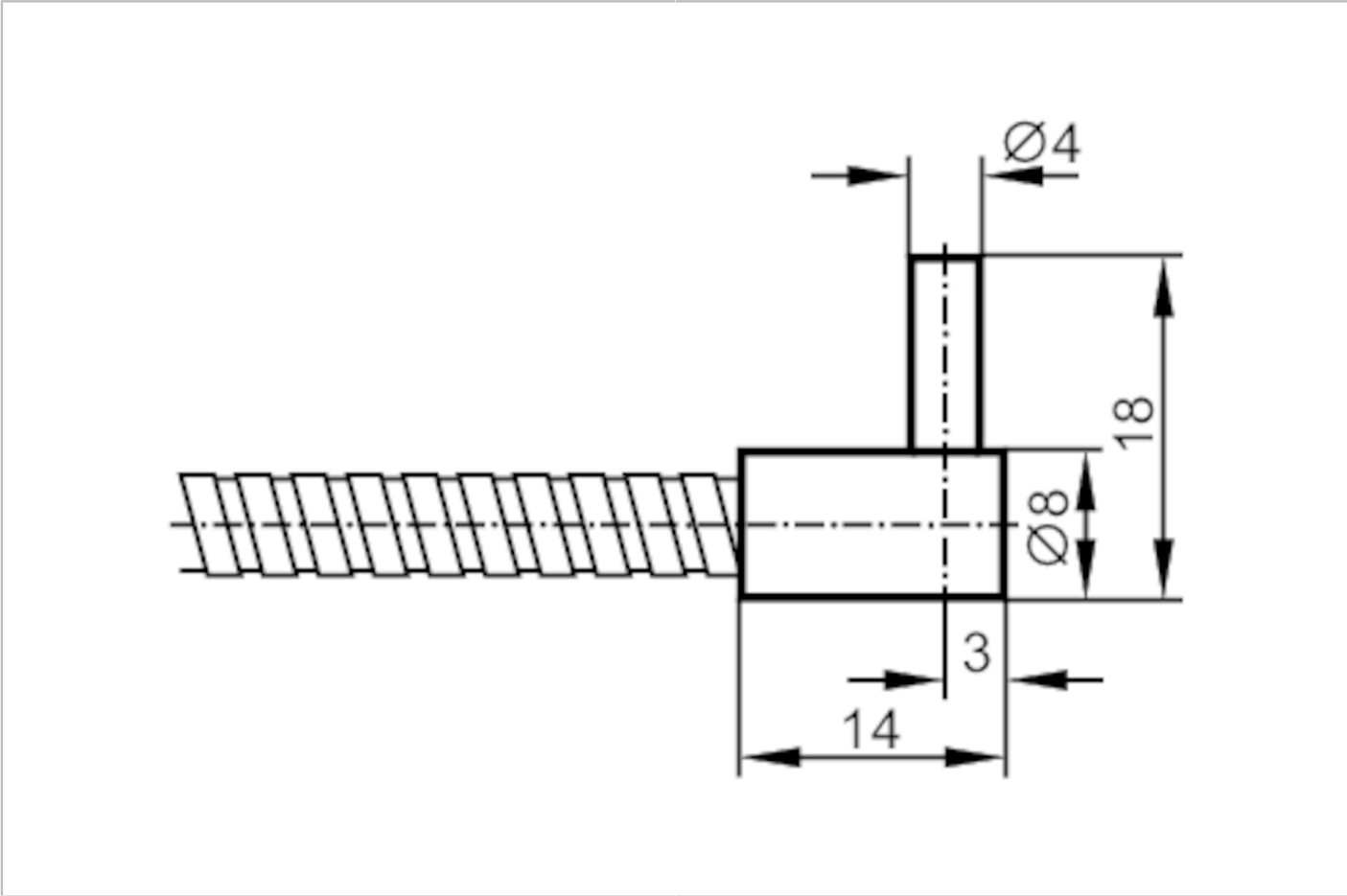

Application		
Function principle		Diffuse reflection sensor
Monitoring range		
Range with fiber optic amplifier type		OKF; OUF
OKF		
Range fiber optics	[mm]	40
OUF		
Range fiber optics	[mm]	40
Operating conditions		
Ambient temperature	[°C]	-40...290
Mechanical data		
Version of sensing head		angled
Sensing head diameter	[mm]	4
Sensing head length	[mm]	10
Total length	[mm]	1000
Min. bending radius	[mm]	20
Material		Adapter: ABS
Fiber material		glass

E20084



Fiber optic diffuse reflection sensor

FT-00-A-A-R4/1M

Fiber head material	aluminum
Fiber sheath material	aluminum
Remarks	
Pack quantity	1 pcs.