




Fiber optic diffuse reflection sensor

FT-00-P-A-E3/S 0,8m

Article no longer available - archive entry

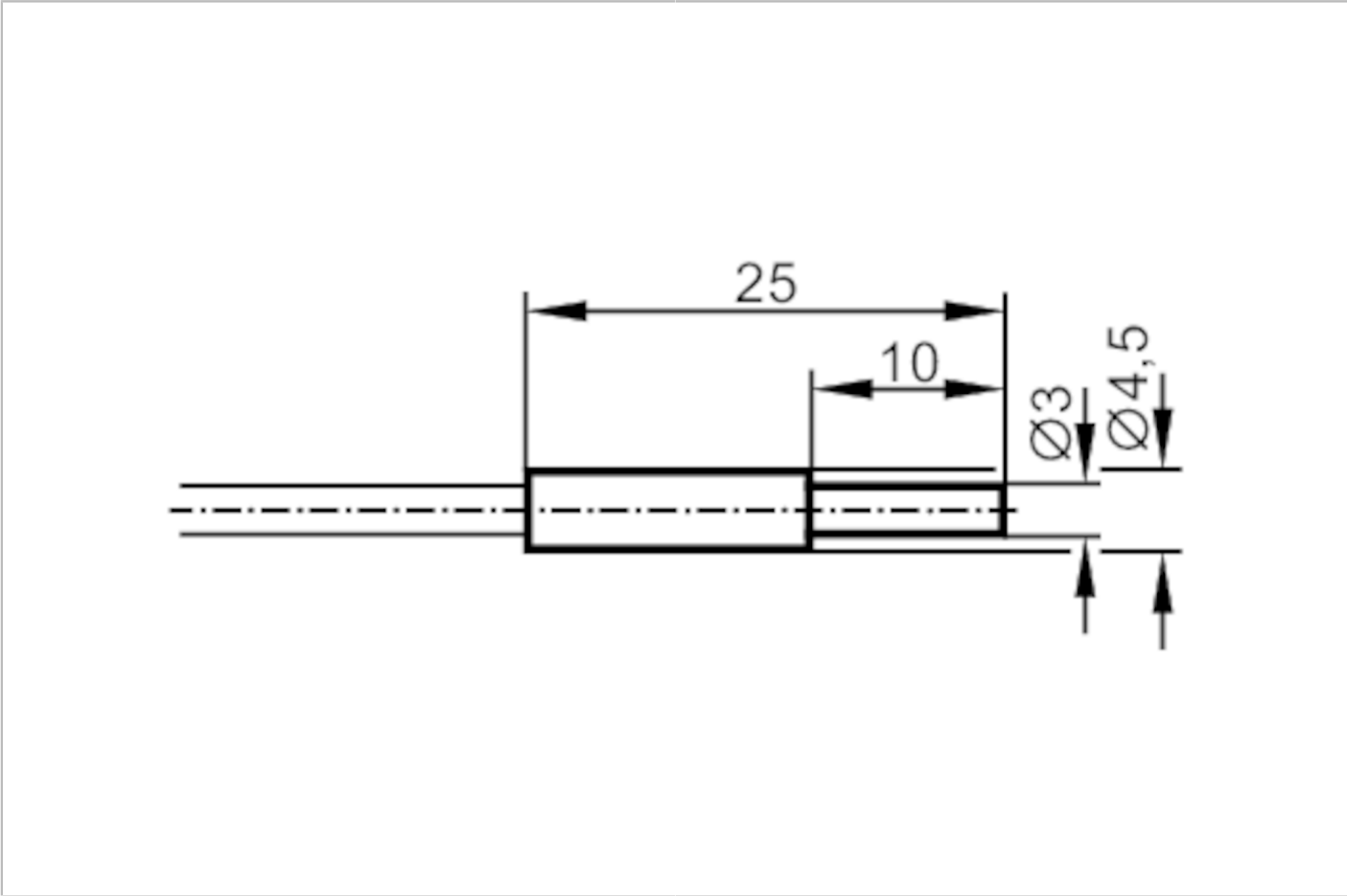

Application	
Function principle	Diffuse reflection sensor
Monitoring range	
Range with fiber optic amplifier type	OKF; OUF
OKF	
Range fiber optics [mm]	40
OUF	
Range fiber optics [mm]	40
Operating conditions	
Ambient temperature [°C]	-20...80
Mechanical data	
Version of sensing head	straight
Sensing head diameter [mm]	3
Sensing head length [mm]	25
Total length [mm]	800
Min. bending radius [mm]	20
Material	Adapter: PPE
Fiber material	glass

E20095



Fiber optic diffuse reflection sensor

FT-00-P-A-E3/S 0,8m

Fiber head material	aluminum
Fiber sheath material	PVC
Remarks	
Pack quantity	1 pcs.