




Fiber optic diffuse reflection sensor

FT-00-A-A-M6/0,3M

Article no longer available - archive entry

Alternative articles: E20055

When selecting an alternative article and accessories please note that technical data may differ!

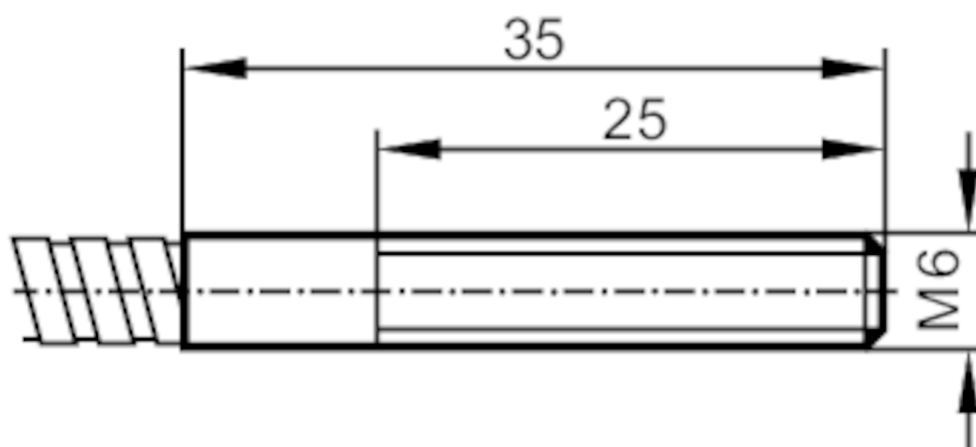

Application

Function principle

Diffuse reflection sensor

Monitoring range

Range with fiber optic amplifier type

OKF; OUF

OKF

Range fiber optics

[mm]

40

OUF

Range fiber optics

[mm]

40

Operating conditions

Ambient temperature

[°C]

-40...290

Mechanical data

Version of sensing head

straight

Sensing head thread

M6

Sensing head length

[mm]

35

Total length

[mm]

300

E20115



Fiber optic diffuse reflection sensor

FT-00-A-A-M6/0,3M

Min. bending radius	[mm]	20
Material		Adapter: ABS
Fiber material		glass
Fiber head material		aluminum
Fiber sheath material		aluminum
Remarks		
Pack quantity		1 pcs.