




Fiber optic through beam sensor

FE-00-A-A-E3/1M

Article no longer available - archive entry

Alternative articles: E20367
When selecting an alternative article and accessories please note that technical data may differ!

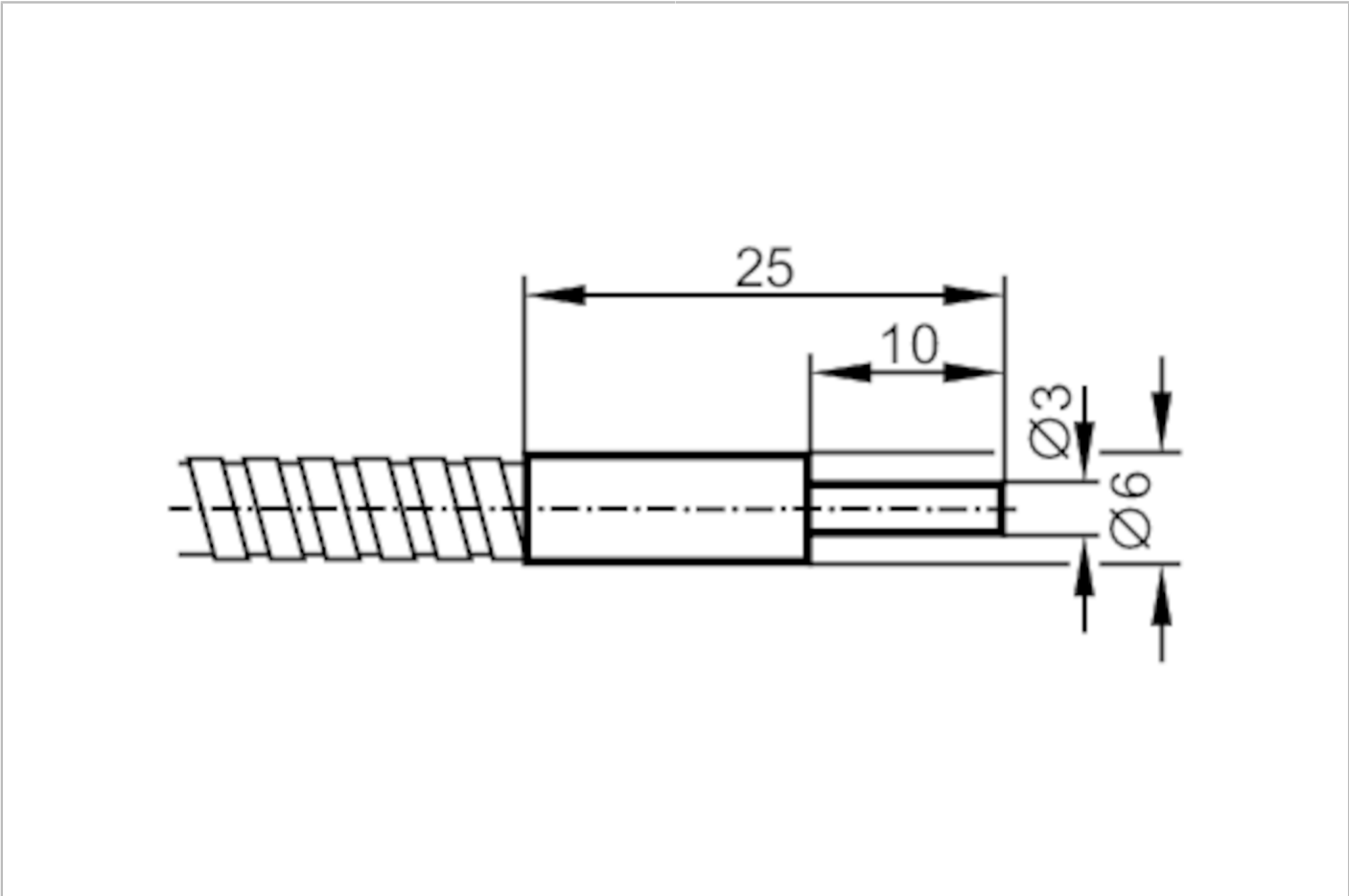

Application	
Function principle	Through-beam sensor
Monitoring range	
Range with fiber optic amplifier type	OKF; OUF
OKF	
Range of fiber optics [mm]	120
OUF	
Range of fiber optics [mm]	120
Operating conditions	
Ambient temperature [°C]	-40...290
Mechanical data	
Version of sensing head	straight
Sensing head diameter [mm]	3
Sensing head length [mm]	10
Total length [mm]	1000

E20141



Fiber optic through beam sensor

FE-00-A-A-E3/1M

Min. bending radius	[mm]	20
Material	Adapter: ABS	
Fiber material	glass	
Fiber head material	aluminum	
Fiber sheath material	aluminum	
Remarks		
Pack quantity	1 pcs.	