




Fiber optic diffuse reflection sensor

FT-00-P-A-E3/2M

Article no longer available - archive entry

Alternative articles: E20350
When selecting an alternative article and accessories please note that technical data may differ!

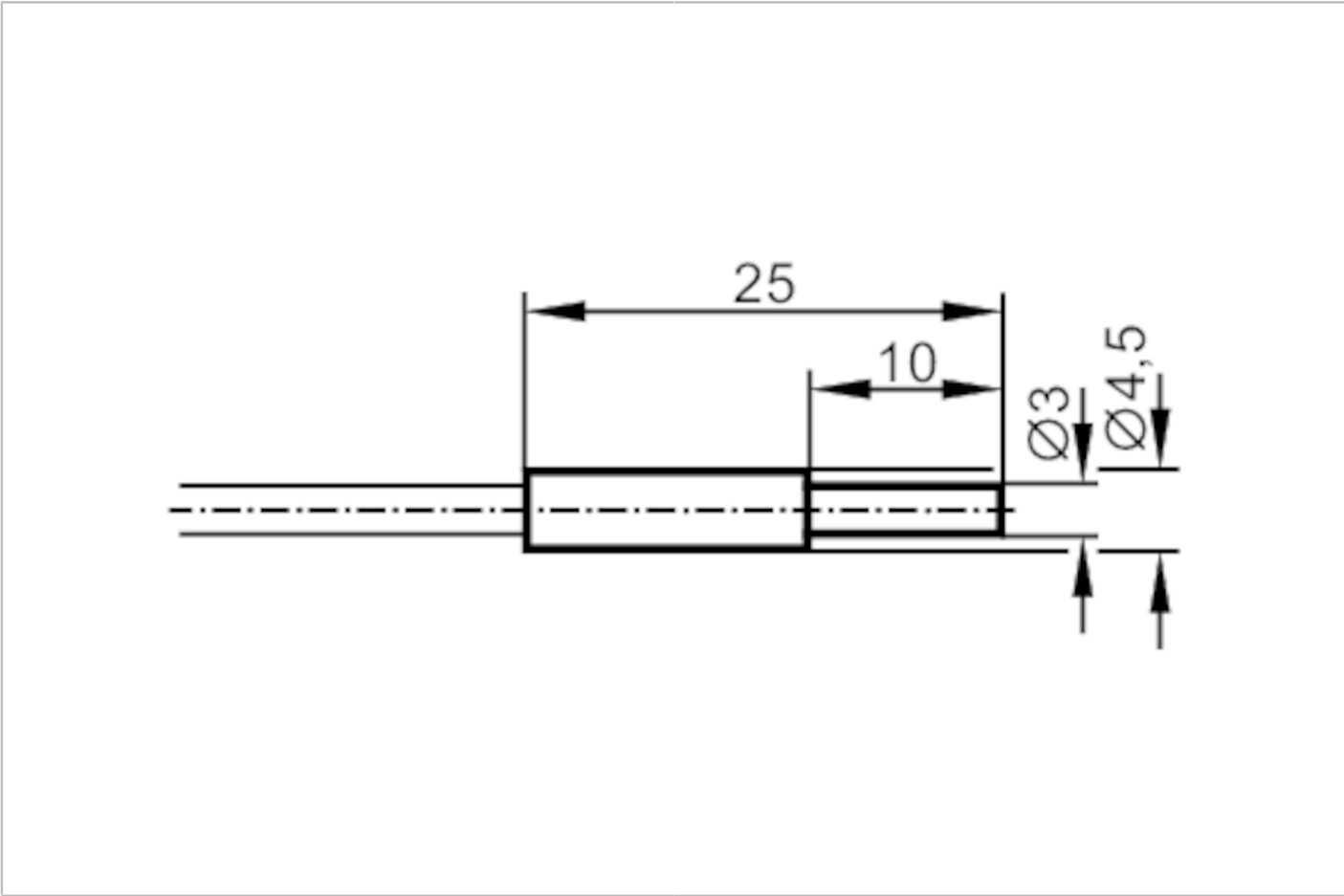

Application	
Function principle	Diffuse reflection sensor
Monitoring range	
Range with fiber optic amplifier type	OKF; OUF
OKF	
Range fiber optics [mm]	32
OUF	
Range fiber optics [mm]	32
Operating conditions	
Ambient temperature [°C]	-20...80
Mechanical data	
Version of sensing head	straight
Sensing head diameter [mm]	3
Sensing head length [mm]	25
Total length [mm]	2000

E20144



Fiber optic diffuse reflection sensor

FT-00-P-A-E3/2M

Min. bending radius	[mm]	20
Material		Adapter: PPE
Fiber material		glass
Fiber head material		aluminum
Fiber sheath material		PVC
Remarks		
Pack quantity		1 pcs.