




Fiber optic through beam sensor

FE-00-P-A-E2,5/2m

Article no longer available - archive entry

Alternative articles: E20359
When selecting an alternative article and accessories please note that technical data may differ!

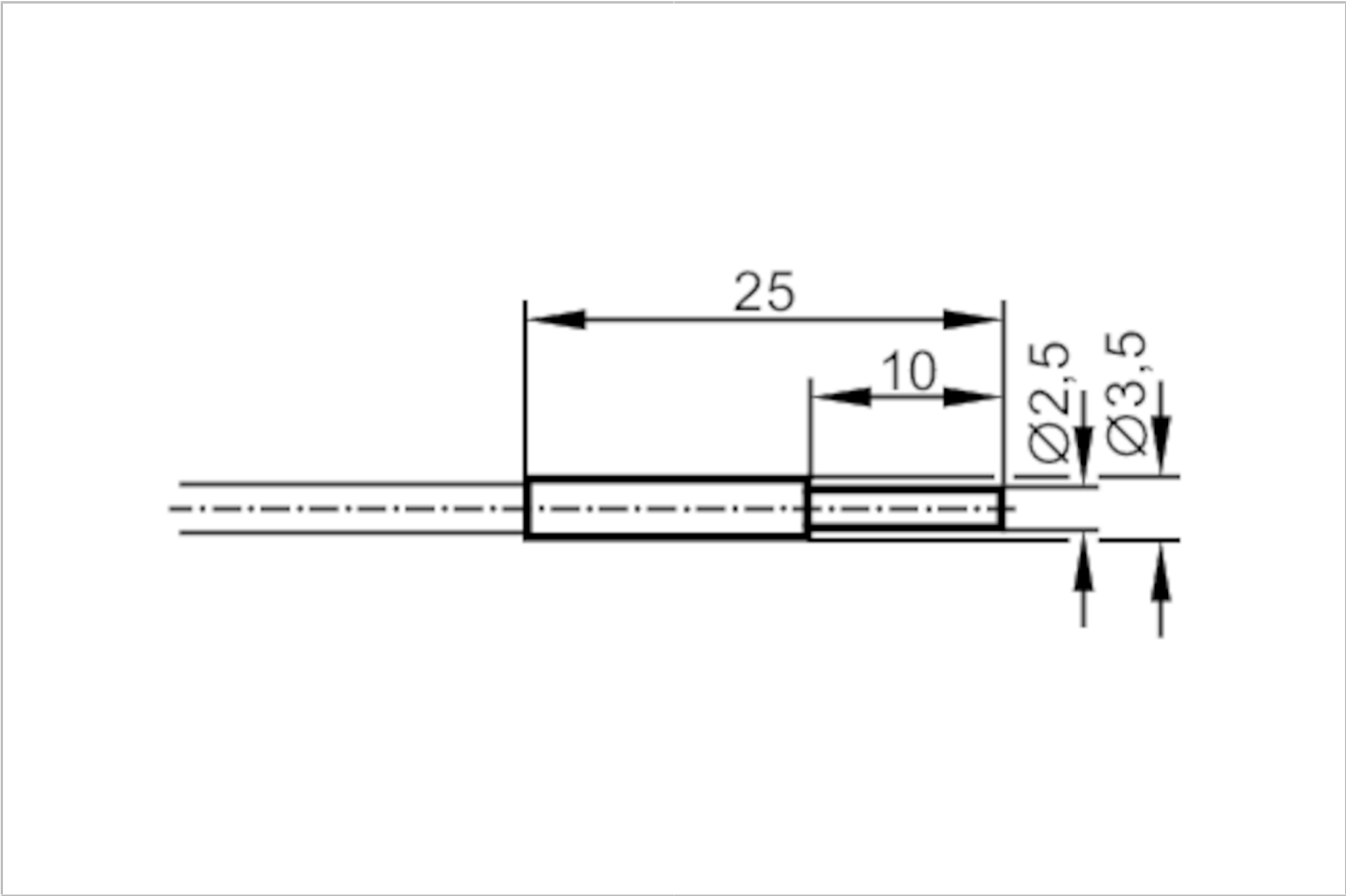

Application	
Function principle	Through-beam sensor
Monitoring range	
Range with fiber optic amplifier type	OKF; OUF
OKF	
Range of fiber optics [mm]	96
OUF	
Range of fiber optics [mm]	96
Operating conditions	
Ambient temperature [°C]	-20...80
Mechanical data	
Version of sensing head	straight
Sensing head diameter [mm]	2.5
Sensing head length [mm]	10
Total length [mm]	2000

E20146



Fiber optic through beam sensor

FE-00-P-A-E2,5/2m

Min. bending radius	[mm]	10
Material	Adapter: PPE	
Fiber material	glass	
Fiber head material	aluminum	
Fiber sheath material	PVC	
Remarks		
Pack quantity	1 pcs.	