

E20148




Fiber optic diffuse reflection sensor

FT-30-A-A-M8/2M

Article to be discontinued

Alternative articles: E20137
When selecting an alternative article and accessories please note that technical data may differ!

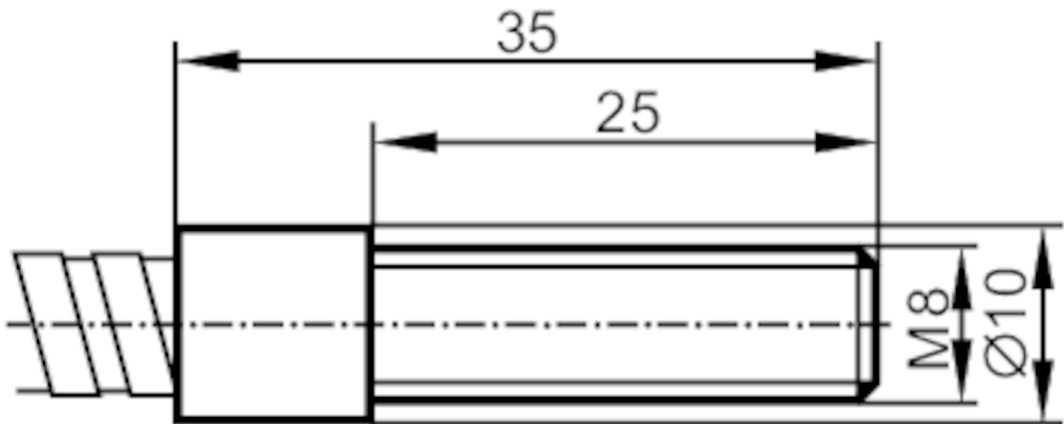

Application	
Function principle	Diffuse reflection sensor
Monitoring range	
Range with fiber optic amplifier type	OIF
OIF	
Range fiber optics [mm]	56
Operating conditions	
Ambient temperature [°C]	-40...290
Mechanical data	
Weight [g]	164
Version of sensing head	straight
Sensing head thread	M8
Total length [mm]	2000
Min. bending radius [mm]	30; (for fixed installation)
Fiber arrangement	⓪

E20148



Fiber optic diffuse reflection sensor

FT-30-A-A-M8/2M

Material	Adapter: PA
Fiber material	glass
Fiber head material	aluminum
Fiber sheath material	aluminum
Accessories	
Items supplied	Hexagon nuts: 2 x M8, stainless steel
	tooth lock washers: 2
	Knurled nut: 1 x M30
Remarks	
Pack quantity	1 pcs.