




Fiber optic through beam sensor

FE-30-P-A-M6

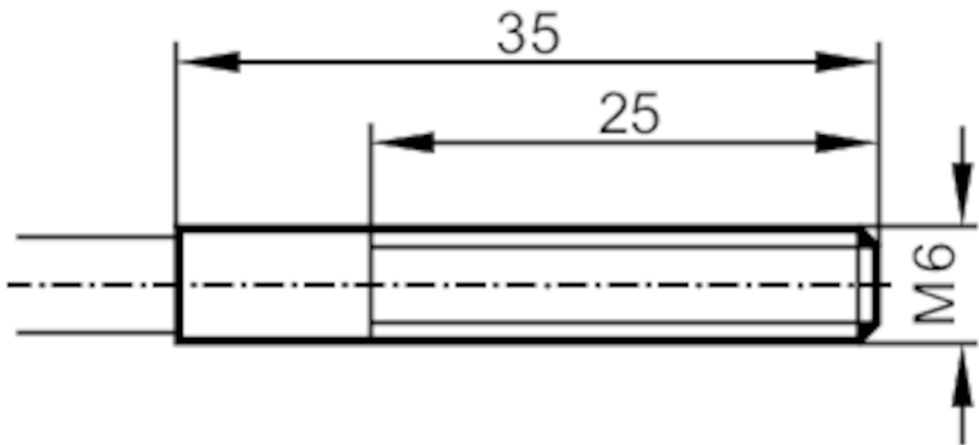

Application		
Function principle	Through-beam sensor	
Application	For use in industrial environments	
Monitoring range		
Range with fiber optic amplifier type	OIF	
OIF		
Range of fiber optics	[mm]	300
Operating conditions		
Ambient temperature	[°C]	-20...80
Mechanical data		
Weight	[g]	98.5
Version of sensing head	straight	
Sensing head thread	M6	
Sensing head length	[mm]	35
Total length	[mm]	600
Min. bending radius	[mm]	30
Fiber arrangement		
Material	Adapter: PA	
Fiber material	glass	

E20164



Fiber optic through beam sensor

FE-30-P-A-M6

Fiber head material	aluminum
Fiber sheath material	PVC
Accessories	
Items supplied	Hexagon nuts: 4 x M6, stainless steel
	tooth lock washers: 4
	Knurled nut: 1 x M30
Remarks	
Pack quantity	1 pcs.