




Fiber optic through beam sensor

FE-30-P-A-R6

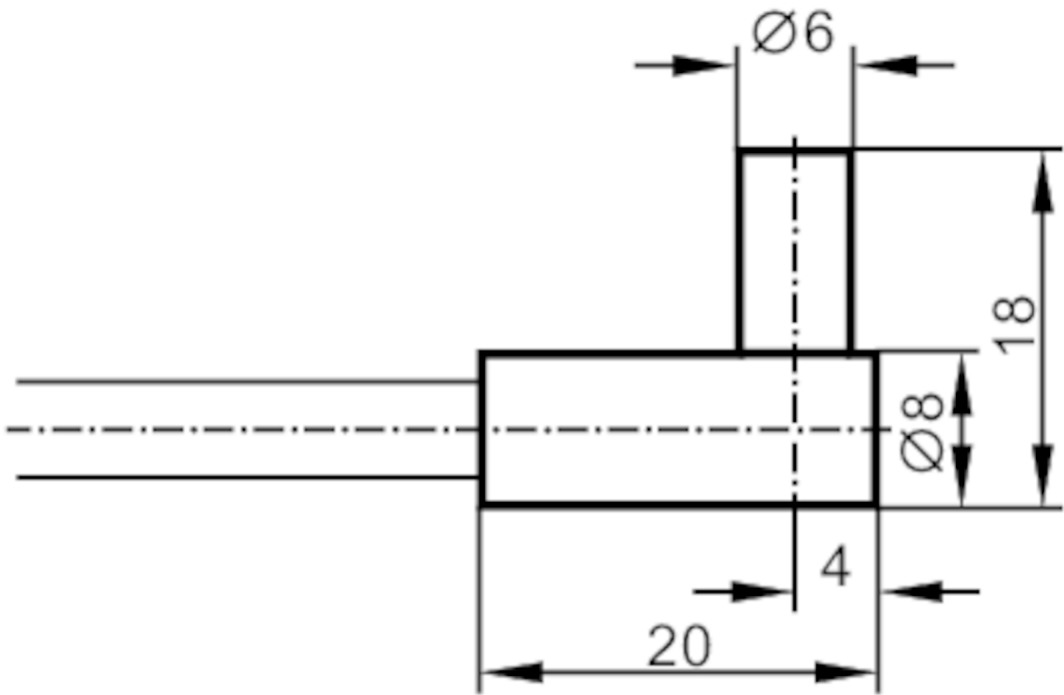

Application		
Function principle		Through-beam sensor
Application		For use in industrial environments
Monitoring range		
Range with fiber optic amplifier type		OIF
OIF		
Range of fiber optics	[mm]	300
Operating conditions		
Ambient temperature	[°C]	-20...80
Mechanical data		
Weight	[g]	107.5
Version of sensing head		angled
Sensing head diameter	[mm]	6
Total length	[mm]	600
Min. bending radius	[mm]	30
Fiber arrangement		●
Material		Adapter: PA
Fiber material		glass
Fiber head material		aluminum

E20165



Fiber optic through beam sensor

FE-30-P-A-R6

Fiber sheath material	PVC
Accessories	
Items supplied	Mounting clamp:, E10221
Remarks	
Pack quantity	1 pcs.