

E20169




Fiber optic diffuse reflection sensor

FT-00-A-A-E3/1,2M

Article no longer available - archive entry

Alternative articles: E20176
When selecting an alternative article and accessories please note that technical data may differ!

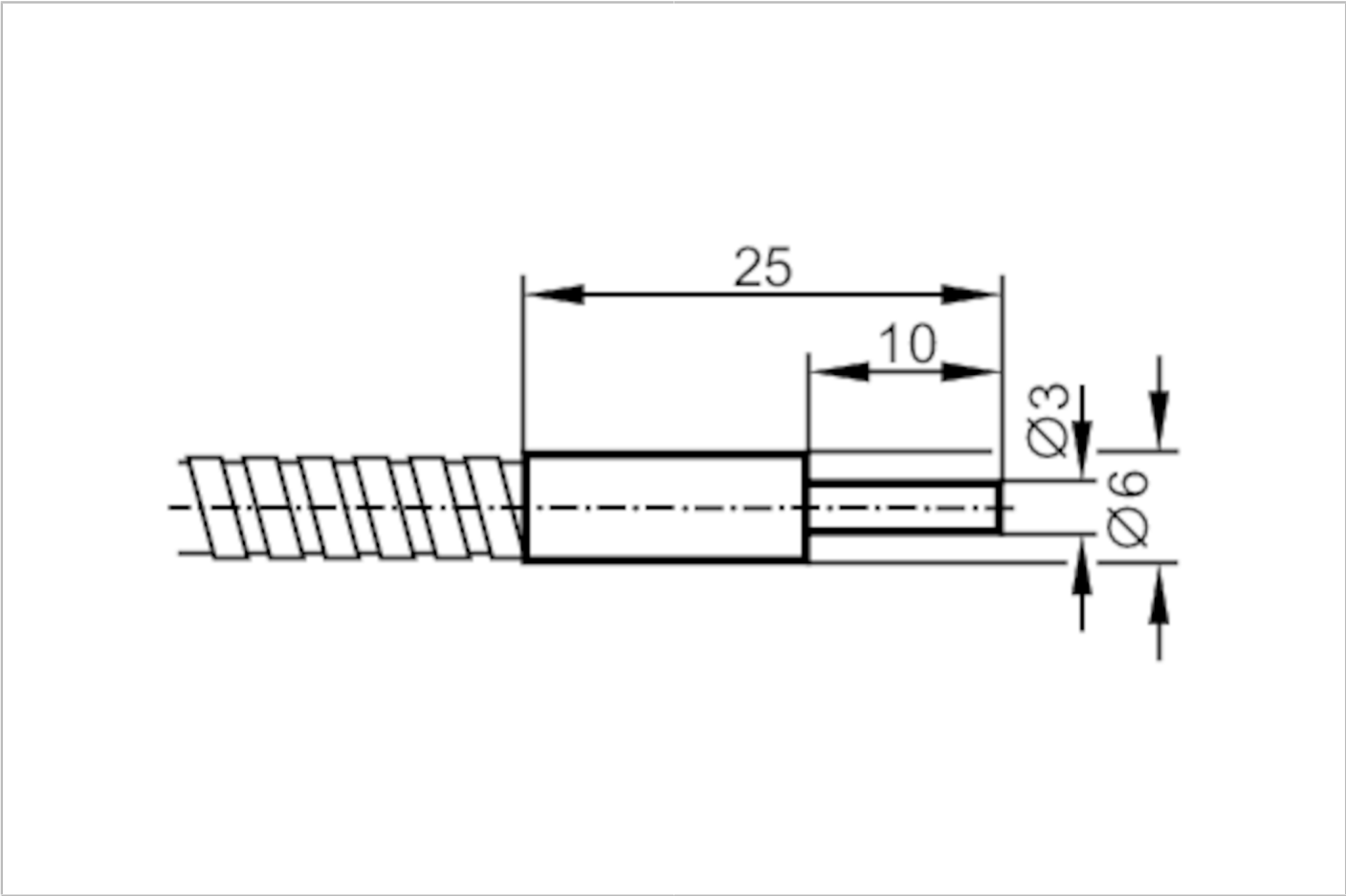

Application	
Function principle	Diffuse reflection sensor
Monitoring range	
Range with fiber optic amplifier type	OKF; OUF
OKF	
Range fiber optics [mm]	38
OUF	
Range fiber optics [mm]	38
Operating conditions	
Ambient temperature [°C]	-40...290
Mechanical data	
Version of sensing head	straight
Sensing head diameter [mm]	3
Sensing head length [mm]	10
Total length [mm]	1200

E20169



Fiber optic diffuse reflection sensor

FT-00-A-A-E3/1,2M

Min. bending radius	[mm]	20
Material		Adapter: ABS
Fiber material		glass
Fiber head material		aluminum
Fiber sheath material		aluminum
Remarks		
Pack quantity		1 pcs.