


Fiber optic diffuse reflection sensor

FT-00-A-V-M6/S

Article no longer available - archive entry

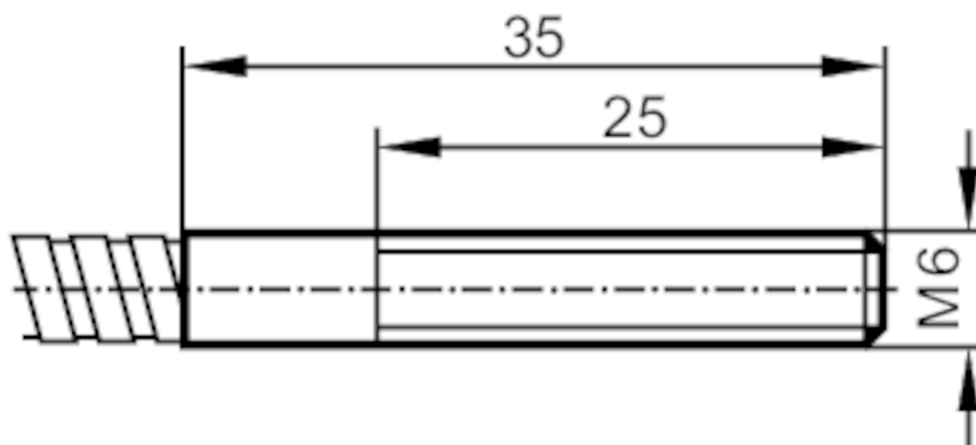

Application

Function principle	Diffuse reflection sensor
--------------------	---------------------------

Monitoring range

Range with fiber optic amplifier type	OKF; OUF
---------------------------------------	----------

OKF

Range fiber optics [mm]	40
-------------------------	----

OUF

Range fiber optics [mm]	40
-------------------------	----

Operating conditions

Ambient temperature [°C]	-40...290
--------------------------	-----------

Mechanical data

Version of sensing head	straight
Sensing head thread	M6
Sensing head length [mm]	35
Total length [mm]	600
Min. bending radius [mm]	20
Material	Adapter: ABS
Fiber material	glass

E20183



Fiber optic diffuse reflection sensor

FT-00-A-V-M6/S

Fiber head material	stainless steel (1.4571/316Ti)
Fiber sheath material	aluminum
Remarks	
Pack quantity	1 pcs.