




Fiber optic through beam sensor

FE-00-A-A-M4/1M

Article no longer available - archive entry

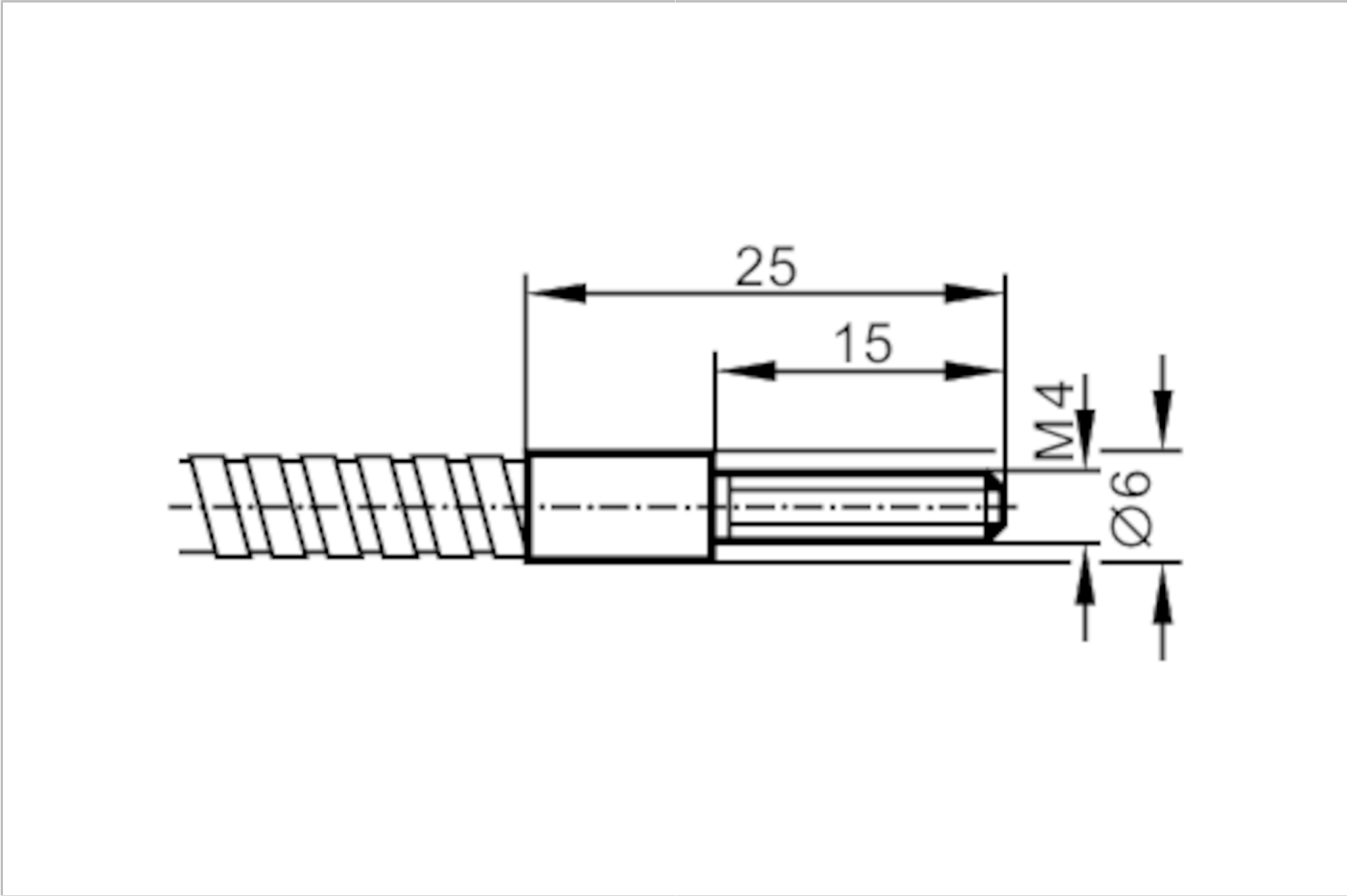

Application		
Function principle		Through-beam sensor
Monitoring range		
Range with fiber optic amplifier type		OKF; OUF
OKF		
Range of fiber optics	[mm]	120
OUF		
Range of fiber optics	[mm]	120
Operating conditions		
Ambient temperature	[°C]	-40...290
Mechanical data		
Weight	[g]	74
Version of sensing head		straight
Sensing head thread		M4
Sensing head length	[mm]	15
Total length	[mm]	1000
Min. bending radius	[mm]	20; (for fixed installation)
Fiber arrangement		

E20186



Fiber optic through beam sensor

FE-00-A-A-M4/1M

Material	Adapter: ABS
Fiber material	glass
Fiber head material	aluminum
Fiber sheath material	aluminum
Accessories	
Items supplied	Hexagon nuts: 4 x M4
	tooth lock washers: 4
	Knurled nut: 1 x M11
Remarks	
Pack quantity	1 pcs.