




Fiber optic diffuse reflection sensor

FT-00-M6

Article to be discontinued

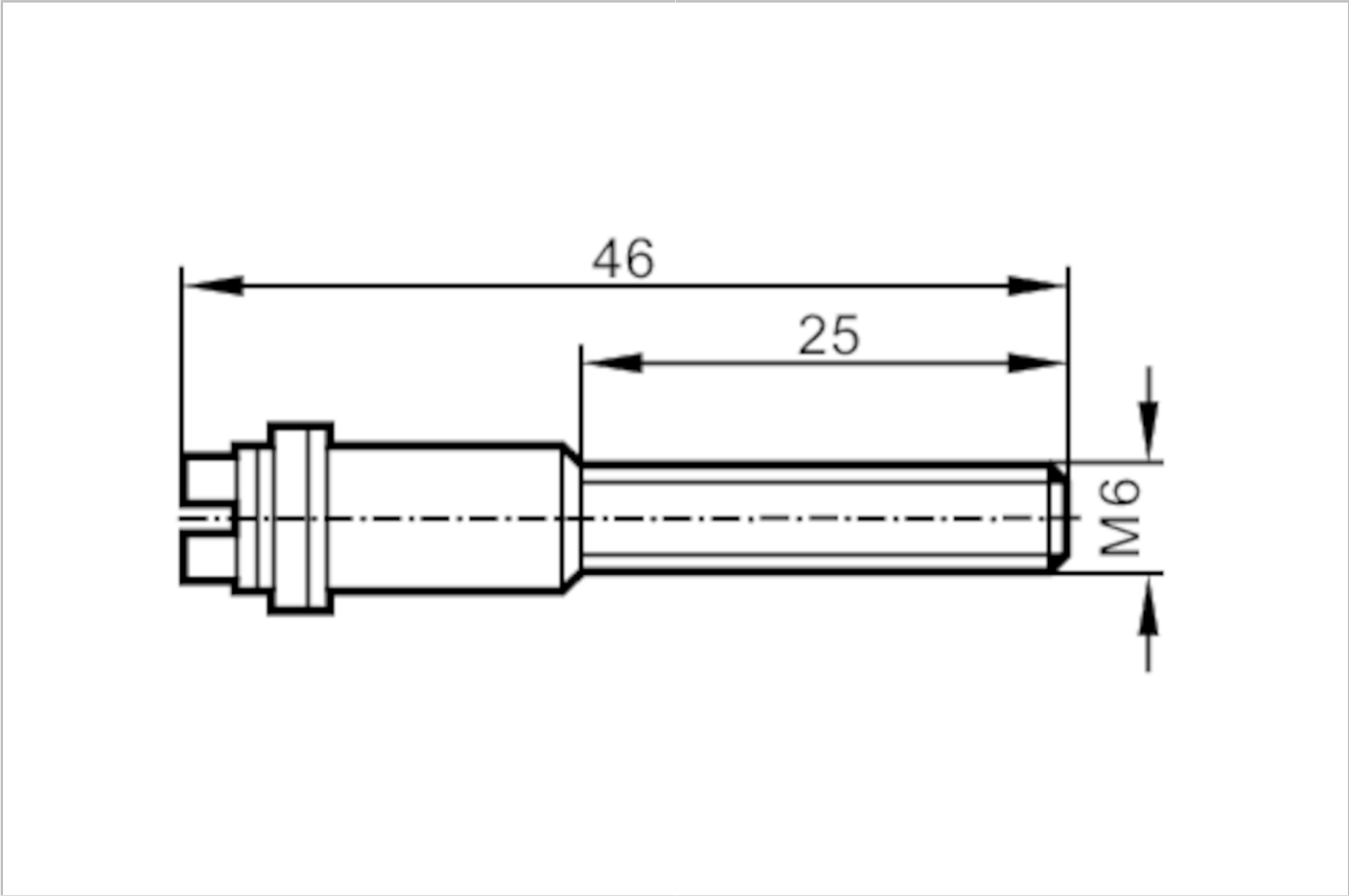

Application		
Function principle		Diffuse reflection sensor
Monitoring range		
Range with fiber optic amplifier type		OKF; OUF; OOF
OKF		
Range fiber optics	[mm]	40
OOF		
Range fiber optics	[mm]	200
OUF		
Range fiber optics	[mm]	40
Operating conditions		
Ambient temperature	[°C]	-25...80
Mechanical data		
Weight	[g]	20.7
Version of sensing head		straight; with adapter for direct mounting
Total length	[mm]	26
Fiber arrangement		
Fiber material		glass

E20215



Fiber optic diffuse reflection sensor

FT-00-M6

Fiber head material	stainless steel (1.4305 / 303)
Accessories	
Items supplied	Hexagon nuts: 4 x M6, stainless steel
	tooth lock washers: 2
	Knurled nut: 1 x M11
Remarks	
Pack quantity	1 pcs.