




Fiber optic through beam sensor

FE-30-P-A-M6/2M

Article no longer available - archive entry

Alternative articles: E20328
When selecting an alternative article and accessories please note that technical data may differ!

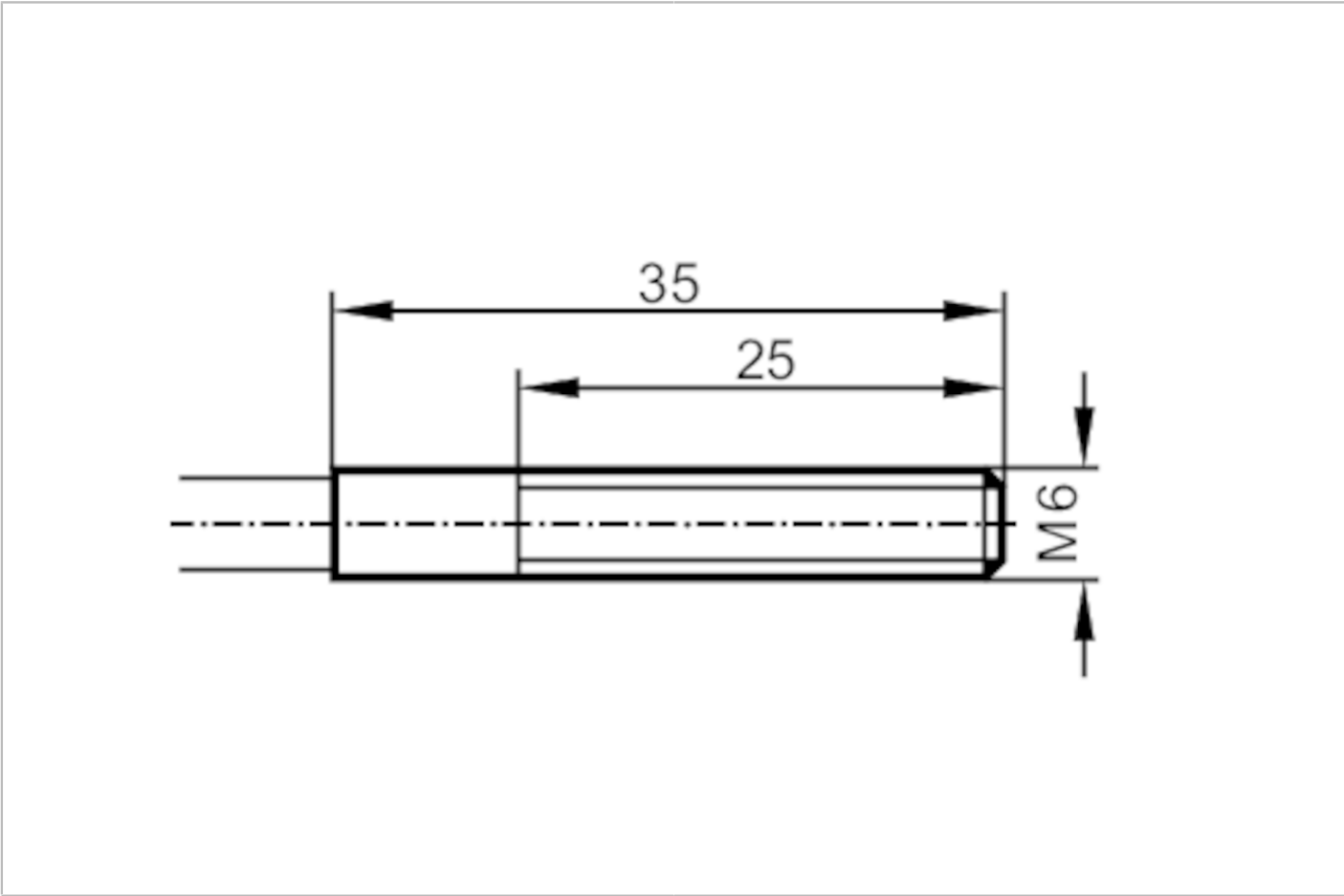

Application	
Function principle	Through-beam sensor
Monitoring range	
Range with fiber optic amplifier type	OIF
OIF	
Range of fiber optics [mm]	270
Operating conditions	
Ambient temperature [°C]	-20...80
Mechanical data	
Version of sensing head	straight
Sensing head thread	M6
Sensing head length [mm]	35
Total length [mm]	2000
Min. bending radius [mm]	30
Fiber arrangement	●

E20217



Fiber optic through beam sensor

FE-30-P-A-M6/2M

Material	Adapter: PA
Fiber material	glass
Fiber head material	aluminum
Fiber sheath material	PVC
Remarks	
Pack quantity	1 pcs.