


Fiber optic diffuse reflection sensor

FT-30-P-A-M8/2M

Article no longer available - archive entry

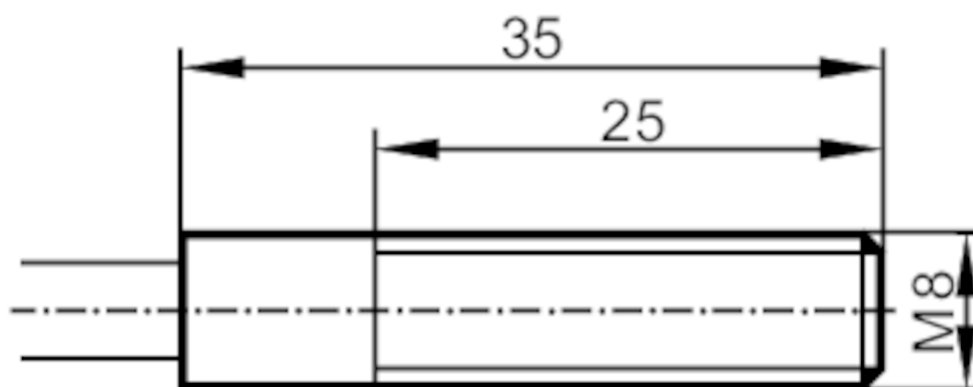

Application

Function principle

Diffuse reflection sensor

Monitoring range

Range with fiber optic amplifier type

OIF

OIF

Range fiber optics

[mm]

56

Operating conditions

Ambient temperature

[°C]

-20...80

Mechanical data

Version of sensing head

straight

Sensing head thread

M8

Total length

[mm]

2000

Min. bending radius

[mm]

30

Fiber arrangement



Material

Adapter: PA

Fiber material

glass

Fiber head material

aluminum

Fiber sheath material

PVC

E20221



Fiber optic diffuse reflection sensor

FT-30-P-A-M8/2M

Remarks

Pack quantity	1 pcs.
---------------	--------