




Fiber optic diffuse reflection sensor

FT-30-A-A-R8/5m

Article no longer available - archive entry

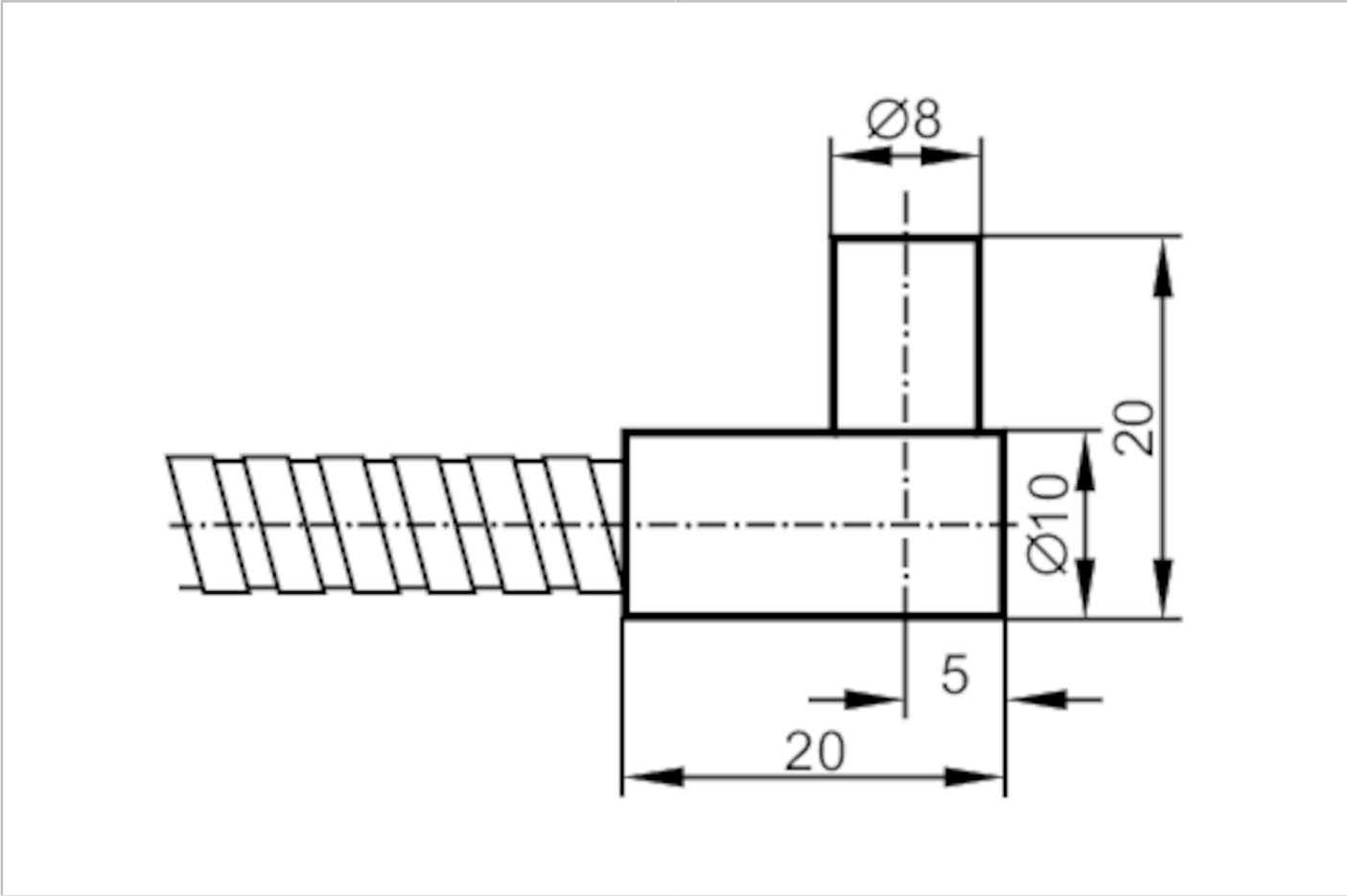

Application	
Function principle	Diffuse reflection sensor
Monitoring range	
Range with fiber optic amplifier type	OIF
OIF	
Range fiber optics [mm]	28
Operating conditions	
Ambient temperature [°C]	-40...290
Mechanical data	
Version of sensing head	angled
Total length [mm]	5000
Min. bending radius [mm]	30
Material	Adapter: PA
Fiber material	glass
Fiber head material	aluminum
Fiber sheath material	aluminum
Remarks	
Pack quantity	1 pcs.