




Fiber optic diffuse reflection sensor

FT-00-A-A-M6/1,8m

Article no longer available - archive entry

Alternative articles: E20124
When selecting an alternative article and accessories please note that technical data may differ!

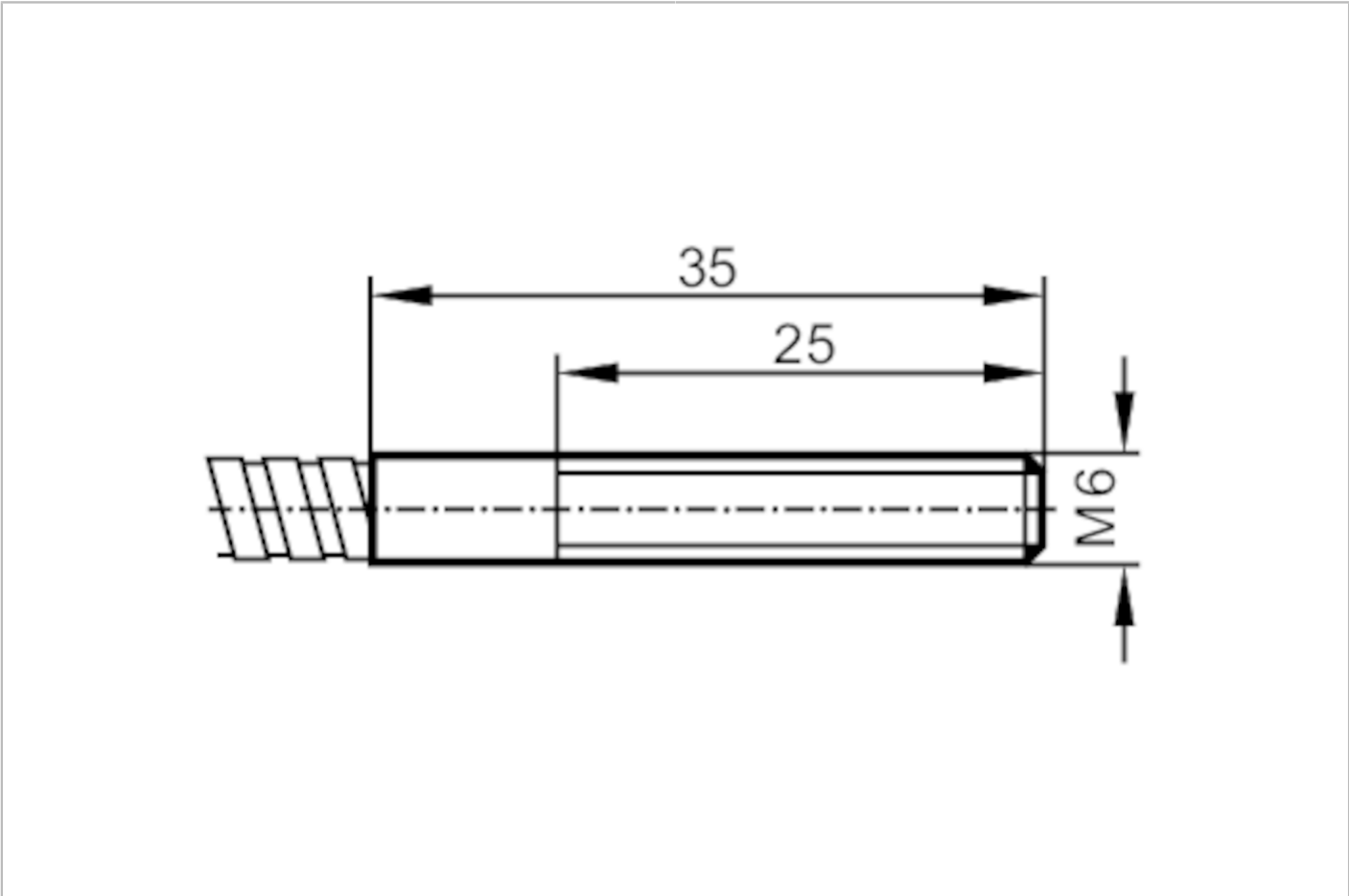

Application	
Function principle	Diffuse reflection sensor
Monitoring range	
Range with fiber optic amplifier type	OKF; OUF
OKF	
Range fiber optics [mm]	35
OUF	
Range fiber optics [mm]	35
Operating conditions	
Ambient temperature [°C]	-40...290
Mechanical data	
Version of sensing head	straight
Sensing head thread	M6
Sensing head length [mm]	35
Total length [mm]	1800

E20243



Fiber optic diffuse reflection sensor

FT-00-A-A-M6/1,8m

Min. bending radius	[mm]	20
Material		Adapter: ABS
Fiber material		glass
Fiber head material		aluminum
Fiber sheath material		aluminum
Remarks		
Pack quantity		1 pcs.