




Fiber optic diffuse reflection sensor

FT-00-A-A-M6/2,6M

Article no longer available - archive entry

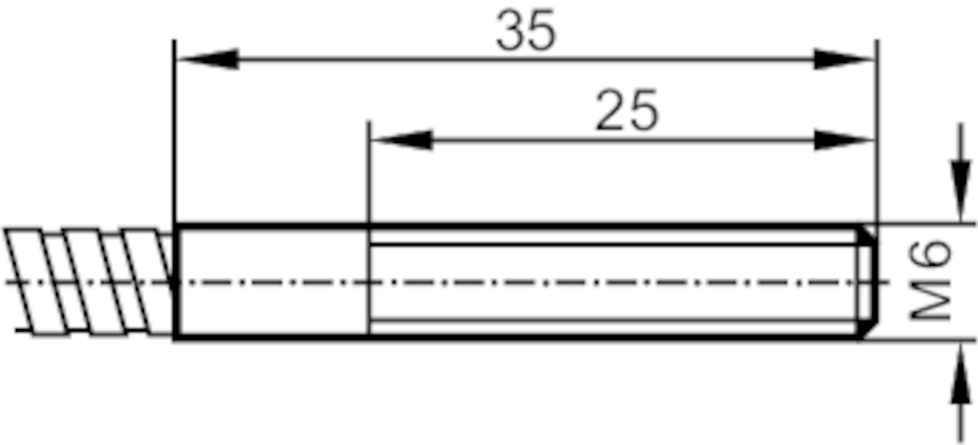

Application	
Function principle	Diffuse reflection sensor
Monitoring range	
Range with fiber optic amplifier type	OKF; OUF
OKF	
Range fiber optics [mm]	28
OUF	
Range fiber optics [mm]	28
Operating conditions	
Ambient temperature [°C]	-40...290
Mechanical data	
Version of sensing head	straight
Sensing head thread	M6
Sensing head length [mm]	35
Total length [mm]	2600
Min. bending radius [mm]	20
Material	Adapter: ABS
Fiber material	glass

E20245



Fiber optic diffuse reflection sensor

FT-00-A-A-M6/2,6M

Fiber head material	aluminum
Fiber sheath material	aluminum
Remarks	
Pack quantity	1 pcs.