




Fiber optic diffuse reflection sensor

FT-00-A-A-M6/2,1m

Article no longer available - archive entry

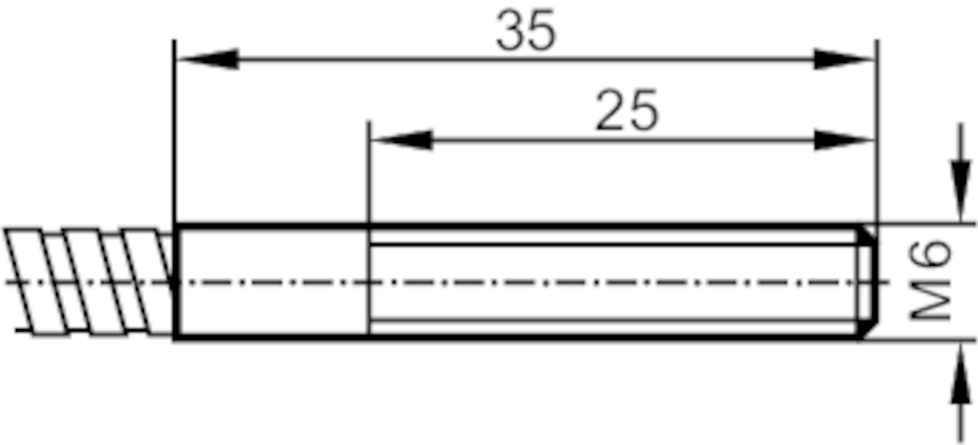

Application		
Function principle		Diffuse reflection sensor
Monitoring range		
Range with fiber optic amplifier type		OKF; OUF
OKF		
Range fiber optics	[mm]	30
OUF		
Range fiber optics	[mm]	30
Operating conditions		
Ambient temperature	[°C]	-40...290
Mechanical data		
Version of sensing head		straight
Sensing head thread		M6
Sensing head length	[mm]	35
Total length	[mm]	600
Min. bending radius	[mm]	20
Material		Adapter: ABS
Fiber material		glass

E20257



Fiber optic diffuse reflection sensor

FT-00-A-A-M6/2,1m

Fiber head material	aluminum
Fiber sheath material	aluminum
Remarks	
Pack quantity	1 pcs.