




Fiber optic through beam sensor

FE-30-P-A-E3/2M

Article no longer available - archive entry

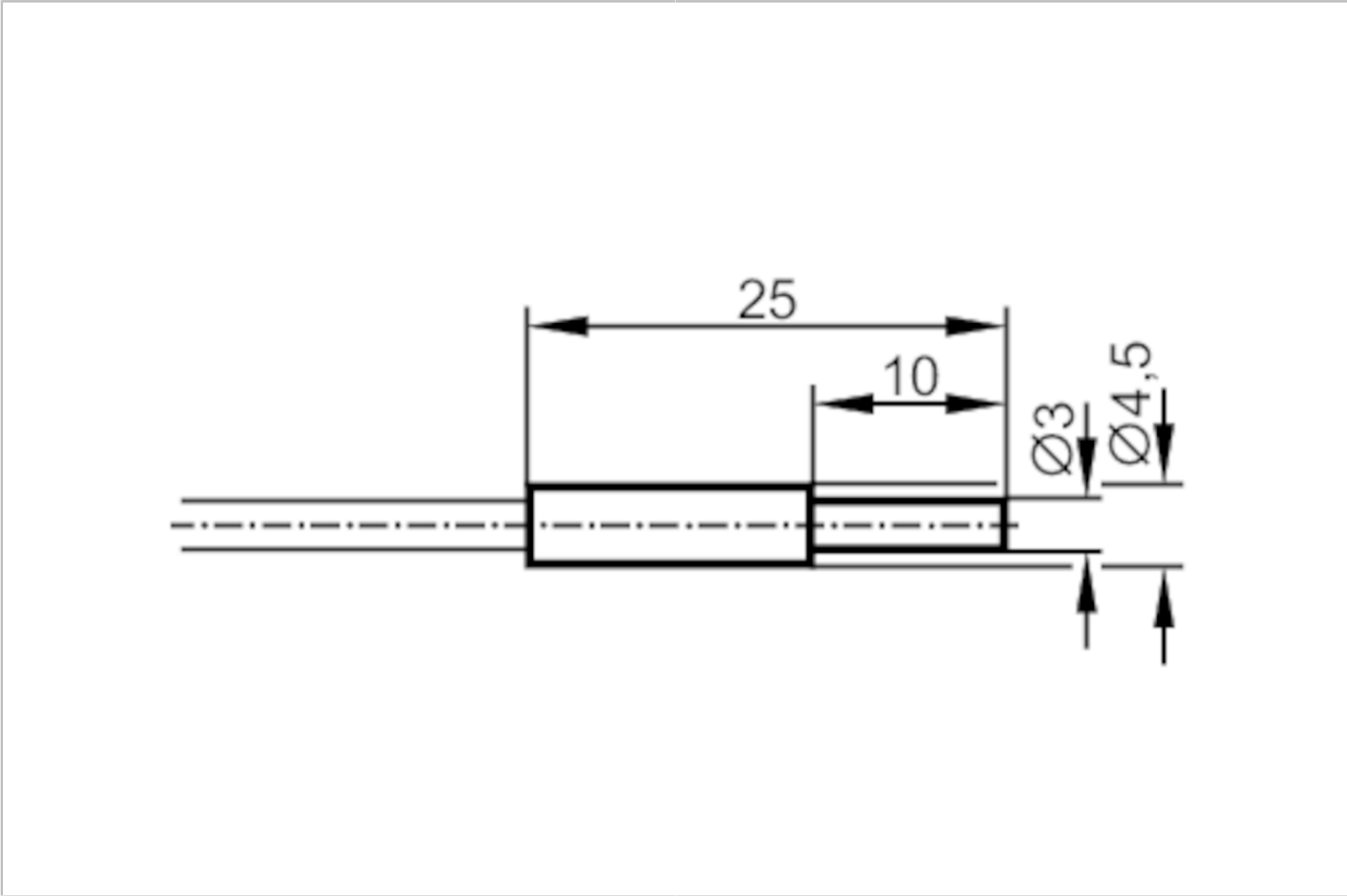

Application		
Function principle	Through-beam sensor	
Monitoring range		
Range with fiber optic amplifier type	OIF	
OIF		
Range of fiber optics	[mm]	80
Operating conditions		
Ambient temperature	[°C]	-20...80
Mechanical data		
Version of sensing head	straight	
Sensing head diameter	[mm]	3
Total length	[mm]	2000
Min. bending radius	[mm]	30
Fiber arrangement		
Material	Adapter: PA	
Fiber material	glass	
Fiber head material	aluminum	
Fiber sheath material	PVC	

E20261



Fiber optic through beam sensor

FE-30-P-A-E3/2M

Accessories	
Items supplied	E20105
Remarks	
Pack quantity	1 pcs.